

**MODLINK MSDD DBL COMBI INSERT USA 2XNEMA 5-15**

GFCI+1xRJ45 female/female

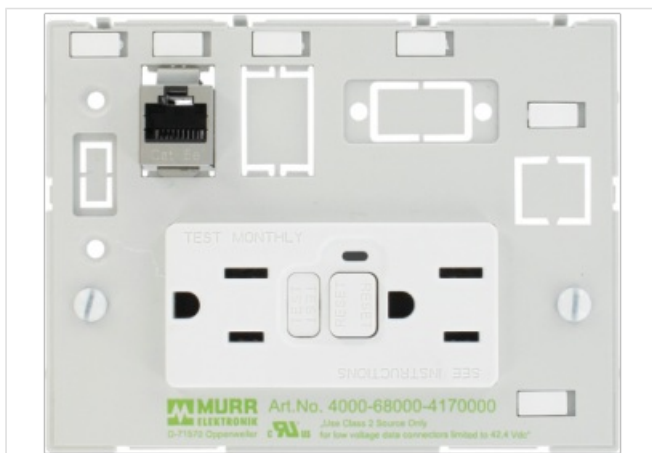
Art.No.: 4000-68000-4170000

Weight: 0.266

Country of origin: CN

Model designation: Fr.Modul-AB-125-15-GFCI-SC+RJ45

2× NEMA-GFCI 5-15 (screw terminals)

1× RJ45, 8-pole metal, CAT5e (female/female)  
with touch protection**[Link to Product](#)****Illustration**

Product may differ from Image

**Header**

Material short text Fr.Modul-AB-125-15-GFCI-SC+RJ45

**Commercial data**

|               |                                                                                                                     |
|---------------|---------------------------------------------------------------------------------------------------------------------|
| URL Webshop   | <a href="https://shop.murrelektronik.com/4000-68000-4170000">https://shop.murrelektronik.com/4000-68000-4170000</a> |
| GTIN          | 4048879463690                                                                                                       |
| ECLASS-6.0    | 27189217                                                                                                            |
| ECLASS-6.1    | 27189217                                                                                                            |
| ECLASS-7.0    | 27189217                                                                                                            |
| ECLASS-7.1    | 27189217                                                                                                            |
| ECLASS-8.0    | 27189217                                                                                                            |
| ECLASS-8.1    | 27189217                                                                                                            |
| ECLASS-9.0    | 27182806                                                                                                            |
| ECLASS-9.1    | 27189217                                                                                                            |
| ECLASS-10.0.1 | 27182806                                                                                                            |
| ECLASS-10.1   | 27182806                                                                                                            |
| ECLASS-11.0   | 27182806                                                                                                            |
| ECLASS-11.1   | 27182806                                                                                                            |
| ECLASS-12.0   | 27182806                                                                                                            |
| ECLASS-13.0   | 27182806                                                                                                            |

|                       |               |
|-----------------------|---------------|
| ECLASS-14.0           | 27182806      |
| ETIM-5.0              | EC000020      |
| ETIM-6.0              | EC000020      |
| ETIM-7.0              | EC000020      |
| ETIM-8.0              | EC000020      |
| customs tariff number | 85366990      |
| EAN                   | 4048879463690 |
| Packaging unit        | 1             |

#### Mechanical data | Mounting data

|        |        |
|--------|--------|
| Height | 88 mm  |
| Width  | 116 mm |
| Depth  | 72 mm  |

#### Environmental characteristics | Climatic

|                          |        |
|--------------------------|--------|
| Storage temperature min. | -40 °C |
| Storage temperature max. | 70 °C  |

#### USA

|                               |                    |
|-------------------------------|--------------------|
| Connection                    | Screw terminals SK |
| No. of poles                  | PE                 |
| Connections per pole          | 2                  |
| Protection contact present    | yes                |
| Connection cross section max. | 6 mm <sup>2</sup>  |
| AWG number max.               | 10                 |
| Operating voltage AC          | 125 V              |
| Operating current             | 15 A               |

#### RJ45

|                                       |                   |
|---------------------------------------|-------------------|
| Family construction form              | RJ45              |
| Looking techniques                    | Snap-in connector |
| Cable category min.                   | Cat5e             |
| Family type Back side                 | RJ45              |
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |
| Current operating max. (UL)           | 175 mA            |