


MODLINK MSDD DBL COMBI INSERT SWITZERLAND

1xRJ45 fem./fem. + RCD opening
Art.No.: 4000-68000-4340001
Weight: 0.157
Country of origin: HU
Model designation: Fr.Modul-CJ-250-10-PT+RJ45+RCD cutout

1× Swiss
1× RJ45, 8-pole metal, CAT5e (female/female)
1× FI cut-out

Link to Product

Illustration

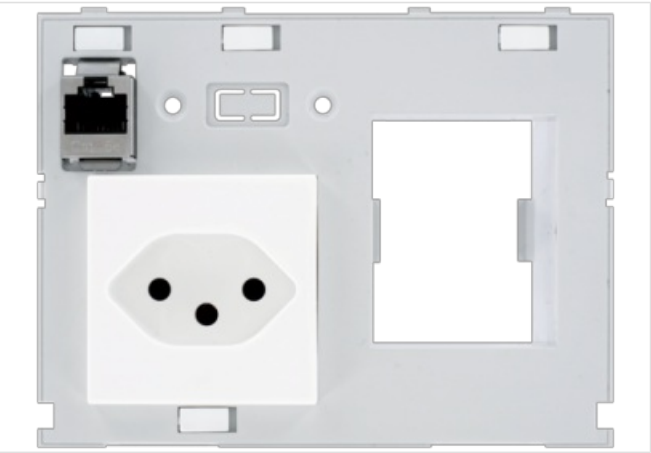

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
ETIM-6.0	EC000020
ETIM-7.0	EC000020
ETIM-8.0	EC000020
customs tariff number	85366990
customs tariff number	85366990
EAN	4048879384612
EAN	4048879384612
Packaging unit	1
Packaging unit	1
Mechanical data Mounting data	

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Storage temperature min.	5 °C
Storage temperature max.	40 °C

Swiss

Connection cross section max.	1,5 mm ²
AWG number max.	16
Operating voltage AC	250 V
Operating current	10 A
Connection	Spring clamp terminals FK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes

RJ45

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector