

**Modlink MSDD-set: Frame 4000-68122-0000000,**

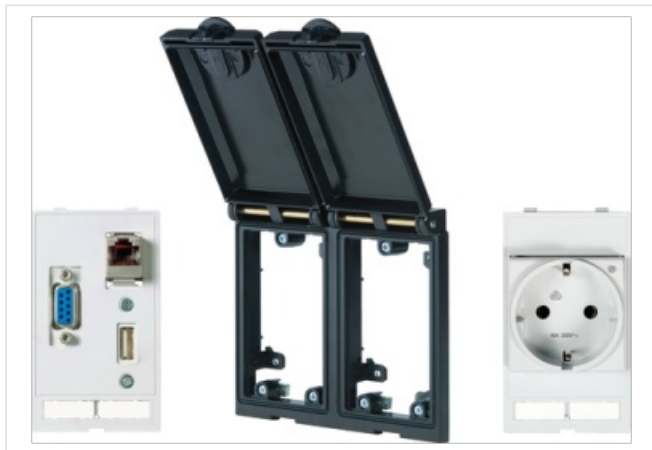
insert 4000-68000-1430000 + 4000-68000-0010000

Art.No.: 4000-68122-1430010

Weight: 0.750 kg

Country of origin: CZ

Model designation: MSDD\_2SW\_9B/S+RJ45+USB\_VDE MIT LED\_

[Link to Product](#)**Illustration**



Product may differ from Image

#### Header

Material short text MSDD\_2SW\_9B/S+RJ45+USB\_VDE MIT LED\_

#### Commercial data

|                       |                                                                                                                     |
|-----------------------|---------------------------------------------------------------------------------------------------------------------|
| URL Webshop           | <a href="https://shop.murrelektronik.com/4000-68122-1430010">https://shop.murrelektronik.com/4000-68122-1430010</a> |
| GTIN                  | 4048879035361                                                                                                       |
| ECLASS-6.0            | 27189217                                                                                                            |
| ECLASS-6.1            | 27189217                                                                                                            |
| ECLASS-7.0            | 27189217                                                                                                            |
| ECLASS-7.1            | 27189217                                                                                                            |
| ECLASS-8.0            | 27189217                                                                                                            |
| ECLASS-8.1            | 27189217                                                                                                            |
| ECLASS-9.0            | 27182806                                                                                                            |
| ECLASS-9.1            | 27189217                                                                                                            |
| ECLASS-10.0.1         | 27182806                                                                                                            |
| ECLASS-10.1           | 27182806                                                                                                            |
| ECLASS-11.0           | 27182806                                                                                                            |
| ECLASS-11.1           | 27182806                                                                                                            |
| ECLASS-12.0           | 27182806                                                                                                            |
| ECLASS-13.0           | 27182806                                                                                                            |
| ECLASS-14.0           | 27182806                                                                                                            |
| ETIM-5.0              | EC002625                                                                                                            |
| ETIM-6.0              | EC002625                                                                                                            |
| ETIM-7.0              | EC002625                                                                                                            |
| ETIM-8.0              | EC002625                                                                                                            |
| customs tariff number | 85366990                                                                                                            |
| EAN                   | 4048879035361                                                                                                       |
| Packaging unit        | 1                                                                                                                   |
| customs tariff number | 85366990                                                                                                            |
| EAN                   | 4048879035361                                                                                                       |
| Packaging unit        | 1                                                                                                                   |

#### Frame

|                                               |                       |
|-----------------------------------------------|-----------------------|
| Material housing                              | Fine zinc die casting |
| Coating housing                               | KTL                   |
| Suitable for installation wall thickness min. | 1 mm                  |
| Suitable for installation wall thickness max. | 5 mm                  |
| Degree of protection (EN IEC 60529)           | IP65                  |
| Operating temperature min.                    | -10 °C                |

|                            |        |
|----------------------------|--------|
| Operating temperature max. | 60 °C  |
| Storage temperature min.   | -25 °C |

#### Shielding plate

|                             |                  |
|-----------------------------|------------------|
| Connection information      | Threaded hole M4 |
| Tightening torque           | 0,9 Nm           |
| Tightening torque tolerance | ± 0,1 Nm         |

#### Germany (VDE)

|                               |                    |
|-------------------------------|--------------------|
| Connection                    | Screw terminals SK |
| No. of poles                  | PE                 |
| Connections per pole          | 2                  |
| Protection contact present    | Yes                |
| Connection cross section max. | 6 mm <sup>2</sup>  |
| AWG number max.               | 10                 |
| Operating voltage AC          | 250 V              |
| Operating current             | 16 A               |
| Status indication LED         | yellow             |

#### USB

|                                       |                   |
|---------------------------------------|-------------------|
| USB specification                     | 3.0               |
| Looking techniques                    | Snap-in connector |
| Data transmission rate max.           | 5.000 Mbit/s      |
| Operating voltage AC                  | 48 V              |
| Operating voltage DC                  | 48 V              |
| Operating current                     | 1,5 A             |
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |

#### SUB-D9

|                                       |                                                |
|---------------------------------------|------------------------------------------------|
| Family construction form              | SUB-D9                                         |
| Gender                                | female                                         |
| No. of poles                          | 9                                              |
| Looking techniques                    | Standard UNC 4-40 screw thread bolt (EN 60807) |
| Family type Back side                 | SUB-D9                                         |
| Gender Rear                           | male                                           |
| Operating voltage AC                  | 48 V                                           |
| Operating voltage DC                  | 48 V                                           |
| Operating current                     | 3 A                                            |
| Operating voltage AC max. (UL-listed) | 30 V                                           |
| Operating voltage DC max. (UL-listed) | 42,4 V                                         |
| Current operating max. (UL)           | 175 mA                                         |

#### RJ45

|                                       |                   |
|---------------------------------------|-------------------|
| Family construction form              | RJ45              |
| Looking techniques                    | Snap-in connector |
| Cable category min.                   | Cat5e             |
| Family type Back side                 | RJ45              |
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |
| Current operating max. (UL)           | 175 mA            |