

Modlink MSDD-set: Frame 4000-68213-0000000,

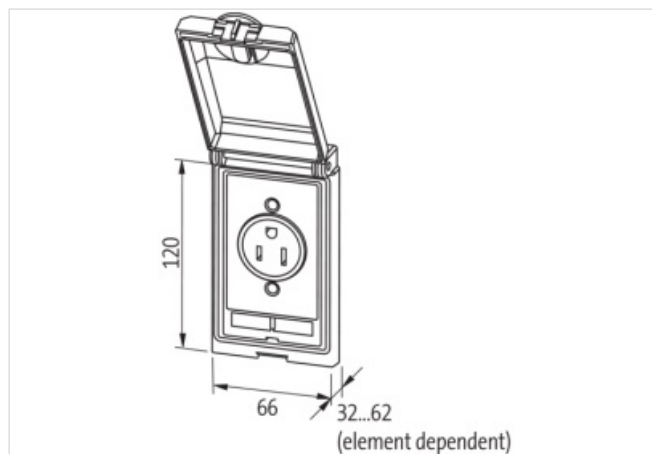
insert 4000-68000-0010000

Art.No.: 4000-68213-0010000

Weight: 0.295

Country of origin: BE

Model designation: MSDD_1MVIPK_VDE MIT LED_

Link to Product**Illustration**

Product may differ from Image

0
0
0
0
0
0
0
0
0

0

0

0

Header

Material short text MSDD_1MVIPK_VDE MIT LED_

Commercial data

URL Webshop	https://shop.murrelektronik.com/4000-68213-0010000
GTIN	4048879033565
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-7.1	27189217
ECLASS-8.0	27189217
ECLASS-8.1	27189217
ECLASS-9.0	27182806
ECLASS-9.1	27189217
ECLASS-10.0.1	27182806
ECLASS-10.1	27182806
ECLASS-11.0	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ECLASS-13.0	27182806
ECLASS-14.0	27182806
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85366990
EAN	4048879033565
Packaging unit	1

Frame

Material housing	Fine zinc die casting
Material lid	PC
Coating housing	surface finished
Color cover	transparent
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-10 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C

Germany (VDE)

Connection	Screw terminals SK
No. of poles	PE
Connections per pole	2
Protection contact present	yes
Connection cross section max.	6 mm ²
AWG number max.	10
Operating voltage AC	250 V

Operating current	16 A
Status indication LED	yellow