

EOL - Modlink MSDD-set: Frame 4000-68523-0000001,

discontinued - End of Life Date: 2024-12-31



Art.No.: 4000-68523-0061201

Weight: 0.281

Country of origin: DE

Model designation: MSDD_2metallic_BS ENGLAND_2XRJ45_

[Link to Product](#)**Illustration**

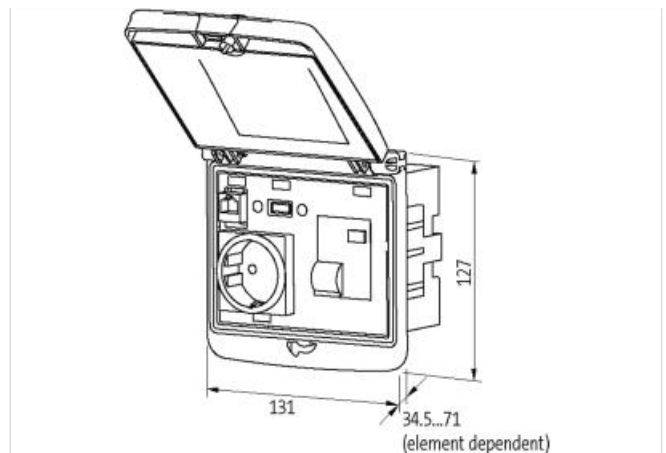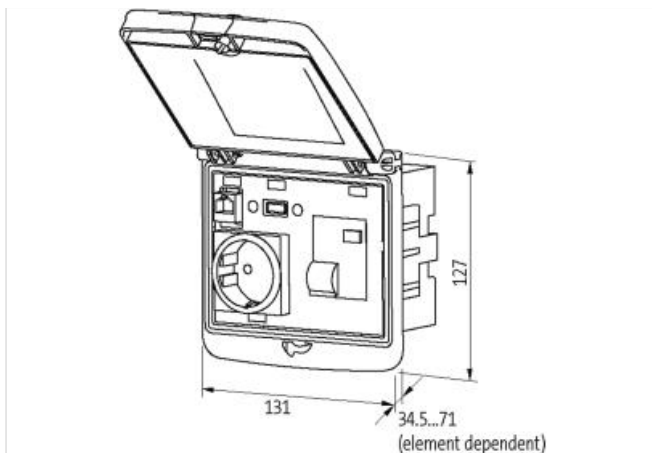

Product may differ from Image

**Commercial data**

ECLASS-6.0	27144001
ECLASS-7.0	27144001
ECLASS-8.0	27144001
ECLASS-9.0	27144001
ETIM-5.0	EC002625
customs tariff number	85366990
customs tariff number	85366990
customs tariff number	85366990
customs tariff number	85366990
EAN	4048879570237
EAN	4048879570237
EAN	4048879570237
EAN	4048879570237
Packaging unit	1
Packaging unit	1
Packaging unit	1
Packaging unit	1

Frame

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Material housing	PA
Color housing	black
Material lid	ABS
Color cover	metallic

Shielding plate

Connection information	Threaded hole M4
Tightening torque	0,9 Nm

England	
Operating voltage AC	250 V
Operating current	13 A
No. of poles	2 + PE
Protection contact present	yes
RJ45	
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector