

**MODLINK MSDD FRAME DBL GRAY**

Closure 3 mm double bit incl. pluggable knob

Art.No.: 4000-68524-0000001

Weight: 0.169

Country of origin: DE

Model designation: Rahmenmodul 2-fach grau 3mm Doppelbart

Frame: plastic PA black

Lid: plastic, PBT gray

Closure: 3 mm double bit


with attachable rotation knob

**Link to Product**

### Illustration



Product may differ from Image

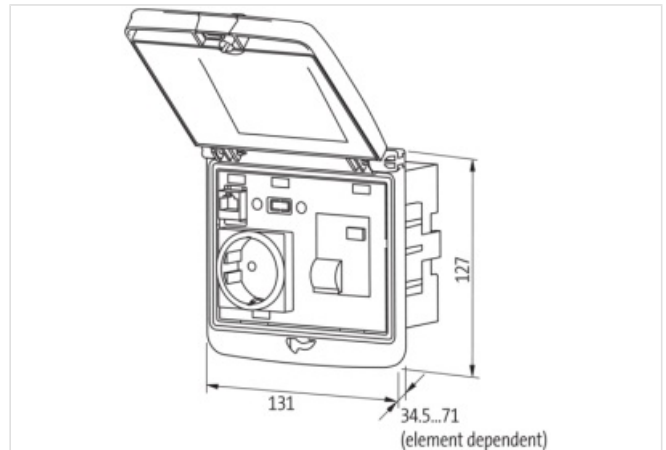

0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0

[illegible]

|                     |                                        |
|---------------------|----------------------------------------|
| Material short text | Rahmenmodul 2-fach grau 3mm Doppelbart |
|---------------------|----------------------------------------|

The information in this Product-PDF has been compiled with the utmost care.  
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2025-10-25

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | [shop@murrinc.com](mailto:shop@murrinc.com) | [shop.murrinc.com](http://shop.murrinc.com)

|                       |                                                                                                                     |
|-----------------------|---------------------------------------------------------------------------------------------------------------------|
| URL Webshop           | <a href="https://shop.murrelektronik.com/4000-68524-0000001">https://shop.murrelektronik.com/4000-68524-0000001</a> |
| GTIN                  | 4048879368889                                                                                                       |
| ECLASS-6.0            | 27144001                                                                                                            |
| ECLASS-6.1            | 27189260                                                                                                            |
| ECLASS-7.0            | 27189260                                                                                                            |
| ECLASS-7.1            | 27189260                                                                                                            |
| ECLASS-8.0            | 27189260                                                                                                            |
| ECLASS-8.1            | 27189260                                                                                                            |
| ECLASS-9.0            | 27182810                                                                                                            |
| ECLASS-9.1            | 27189260                                                                                                            |
| ECLASS-10.0.1         | 27182810                                                                                                            |
| ECLASS-10.1           | 27182810                                                                                                            |
| ECLASS-11.0           | 27182810                                                                                                            |
| ECLASS-11.1           | 27182810                                                                                                            |
| ECLASS-12.0           | 27182810                                                                                                            |
| ECLASS-13.0           | 27182810                                                                                                            |
| ECLASS-14.0           | 27182810                                                                                                            |
| ETIM-5.0              | EC002625                                                                                                            |
| ETIM-6.0              | EC002625                                                                                                            |
| ETIM-7.0              | EC002625                                                                                                            |
| ETIM-8.0              | EC002625                                                                                                            |
| customs tariff number | 85389099                                                                                                            |
| EAN                   | 4048879368889                                                                                                       |
| Packaging unit        | 1                                                                                                                   |

#### Device protection | Electrical

|                                     |      |
|-------------------------------------|------|
| Degree of protection (EN IEC 60529) | IP65 |
|-------------------------------------|------|

#### Mechanical data | Material data

|                  |       |
|------------------|-------|
| Material housing | PA    |
| Color housing    | black |
| Material lid     | PBT   |
| Color cover      | gray  |

#### Mechanical data | Mounting data

|                                               |        |
|-----------------------------------------------|--------|
| Height                                        | 127 mm |
| Width                                         | 131 mm |
| Depth                                         | 43 mm  |
| Suitable for installation wall thickness min. | 1 mm   |
| Suitable for installation wall thickness max. | 5 mm   |

#### Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -30 °C |
| Operating temperature max. | 70 °C  |
| Storage temperature min.   | -30 °C |
| Storage temperature max.   | 80 °C  |

#### Frame

|                                               |        |
|-----------------------------------------------|--------|
| Material housing                              | PA     |
| Color housing                                 | black  |
| Material lid                                  | PBT    |
| Color cover                                   | gray   |
| Suitable for installation wall thickness min. | 1 mm   |
| Suitable for installation wall thickness max. | 5 mm   |
| Degree of protection (EN IEC 60529)           | IP65   |
| Operating temperature min.                    | -30 °C |
| Operating temperature max.                    | 70 °C  |

Storage temperature min. -30 °C