

MSDD pass-through RJ45 CAT5e femal/femal, design silver

Art.No.: 4000-73000-0010000

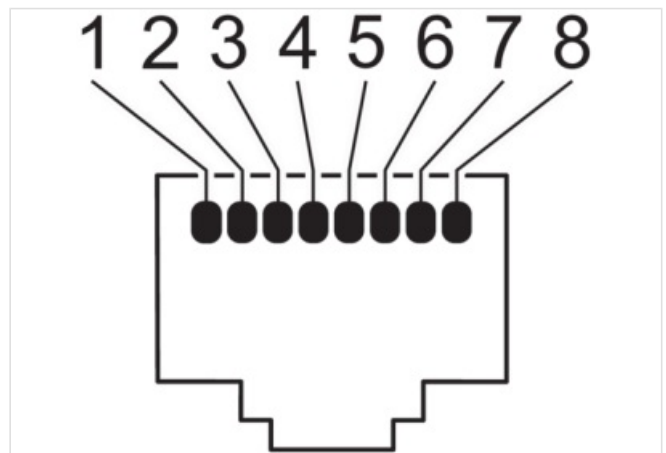
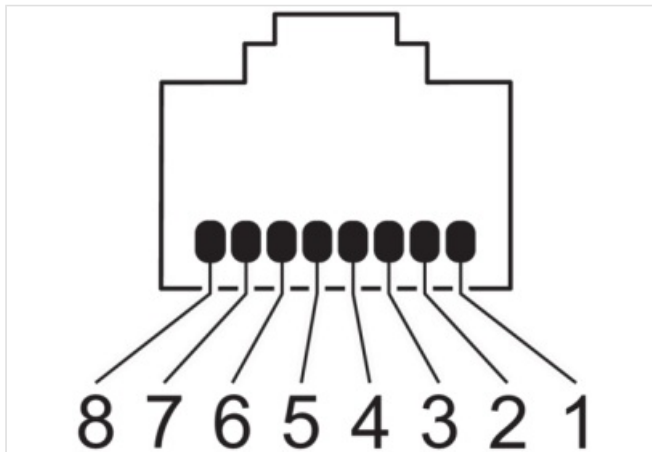
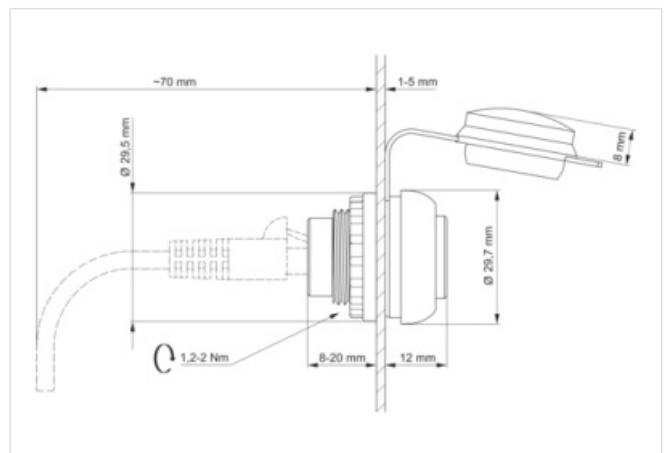
Weight: 0.018

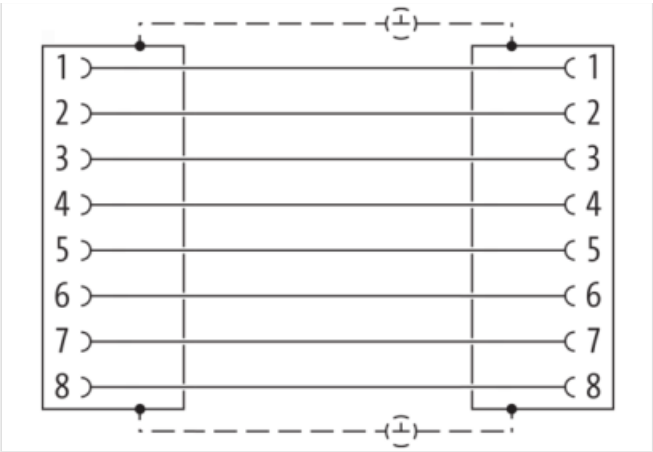
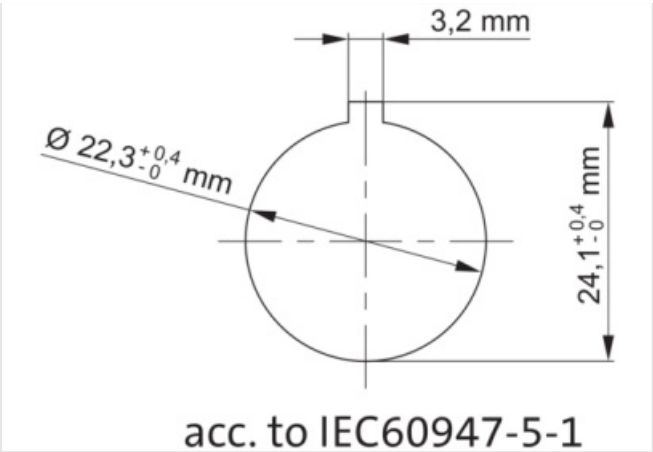
Country of origin: CZ

Model designation: MSDD PT22-S RJ45 CAT5e F/F

Pass-through

1 × RJ45, 8-pole CAT5e (female/female)

[Link to Product](#)**Illustration**



Product may differ from Image



Header	
Material short text	MSDD PT22-S RJ45 CAT5e F/F
Commercial data	
URL Webshop	https://shop.murrelektronik.com/4000-73000-0010000
GTIN	4048879031189
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-7.1	27440515
ECLASS-8.0	27440515
ECLASS-8.1	27440515
ECLASS-9.0	27440515
ECLASS-9.1	27440515
ECLASS-10.0.1	27440515
ECLASS-10.1	27440515
ECLASS-11.0	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ECLASS-13.0	27440515
ECLASS-14.0	27440515
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85366990
EAN	4048879031189
Packaging unit	1
Electrical data Supply	
Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	15 A
Industrial communication	

Data transmission rate max. 1,000 MBit/s

Installation | Connection

Family construction form	RJ47
Gender	female
Gender Rear	female
Cable category min.	Cat5e

Device protection

Shielded	yes
----------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	12, 3R, 4x, 4, 13, 2
Additional condition protection degree	in closed state, inserted

Device protection | Mechanical

Mechanical endurance	750 Cycles
----------------------	------------

Mechanical data | Mounting data

Depth	20 mm
Diameter	295 mm
Mounting depth	70 mm
Diameter cutout	225 mm

Approvals

UL 50E	yes
--------	-----