

MODLINK MSDD FRAME SINGLE TRANSPARENT

with customized printing

Art.No.: 400C-68512-0000001  
Weight: 0.087  
Country of origin: US  
Model designation: Rahmenmodul 1-fach transp. customized


Customized printing  
Frame: plastic PA black  
Lid: plastic, PC transparent  
Closure: 3 mm double bit  
with attachable rotation knob

Link to Product

Illustration



Product may differ from Image

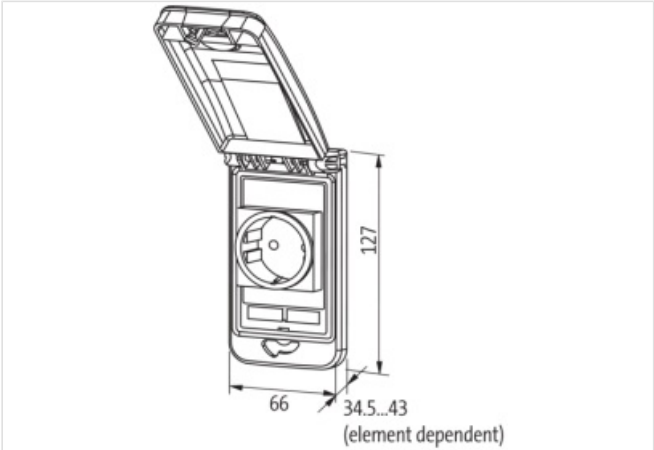

0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0  
0

[illegible]

Material short text	Rahmenmodul 1-fach transp. customized
---------------------	---------------------------------------

The information in this Product-PDF has been compiled with the utmost care.  
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2025-11-13

URL Webshop	<a href="https://shop.murrelektronik.com/400C-68512-0000001">https://shop.murrelektronik.com/400C-68512-0000001</a>
GTIN	4048879689427
ECLASS-6.0	27189217
ECLASS-6.1	27189260
ECLASS-7.0	27189260
ECLASS-7.1	27189260
ECLASS-8.0	27189260
ECLASS-8.1	27189260
ECLASS-9.0	27182810
ECLASS-9.1	27189260
ECLASS-10.0.1	27182810
ECLASS-10.1	27182810
ECLASS-11.0	27182810
ECLASS-11.1	27182810
ECLASS-12.0	27182810
ECLASS-13.0	27182810
ECLASS-14.0	27182810
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85389099
EAN	4048879689427
Packaging unit	1

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

#### Mechanical data | Material data

Material housing	PA
Color housing	Black
Material lid	PC
Color cover	transparent

#### Mechanical data | Mounting data

Height	127 mm
Width	66 mm
Depth	43 mm
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C

#### Frame

Material housing	PA
Color housing	Black
Material lid	PC
Color cover	transparent
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C

Storage temperature min. -30 °C