

**CAP FOR D-BOX M12 6-WAY 5-POLE**

Pot.-sep. 10m PUR/PVC-JB, 12x0,34+5x0,75

Art.No.: 4027077

Weight: 1.66

Country of origin: CZ

Model designation: MVZ-HL M12 MVM6-UHB10.0-MP

for 6-way distribution boxes, 5-pole

PUR/PVC

10.0 m

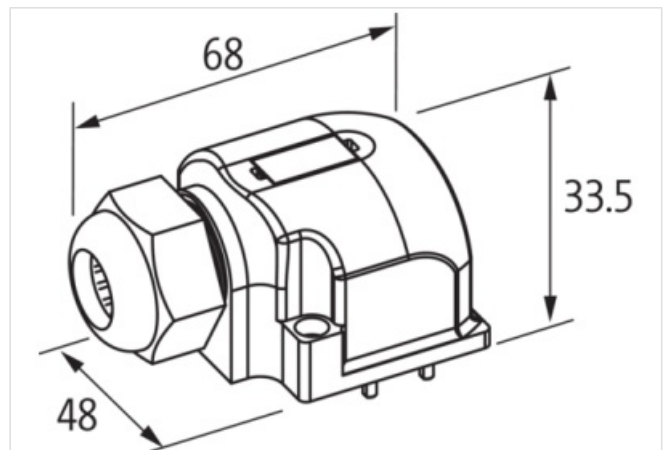
potentially separated

New Art.-No. 8000-86659-3921000

Plastic housings with good resistance against chemicals and oils.

**[Link to Product](#)****Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	<a href="https://shop.murrelektronik.com/4027077">https://shop.murrelektronik.com/4027077</a>
GTIN	4048879058131
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440108
ECLASS-9.1	27440108
ECLASS-10.0.1	27440108
ECLASS-10.1	27440108
ECLASS-11.0	27440108
ECLASS-11.1	27440108
ECLASS-12.0	27440108
ECLASS-13.0	27440108
ECLASS-14.0	27440108
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585

ETIM-8.0	EC002585
EAN	4048879058131

**Electrical data | Supply**

Total current max.	8 A
--------------------	-----

**Mechanical data | Mounting data**

Height	33 mm
Width	48 mm
Depth	68 mm

**Connection type 2**

Family construction form	M12
No. of poles	5
Coding	A
Gender	female
Color contact carrier	black
PIN 1	+
PIN 2	NC S 2
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Family construction form	free cable end
No. of poles	17
Color contact carrier	gray