

CAP BIG WITH PLUG.SPRING-TERM 21-POLE



For use with 4-,6-,8-way d-box M12 5--pole

Art.No.: 4127795
Weight: 0.048
Country of origin: CZ
Model designation: MVZ12-HFK21H MVMX 21P.

Cap for 4-, 6-, and 8-way distribution box, 5-pole
Spring clamp plug-in terminals
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

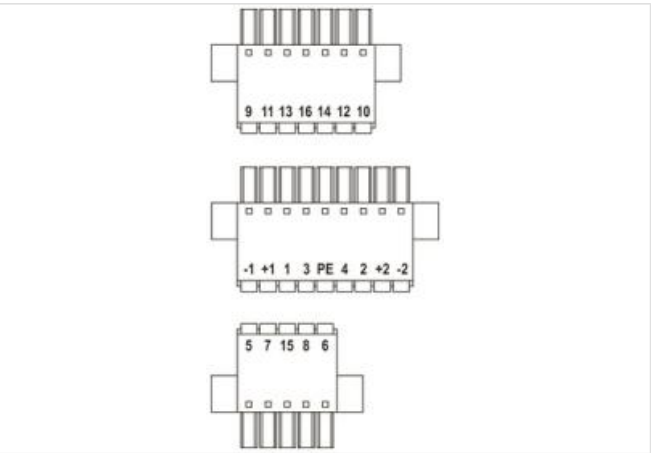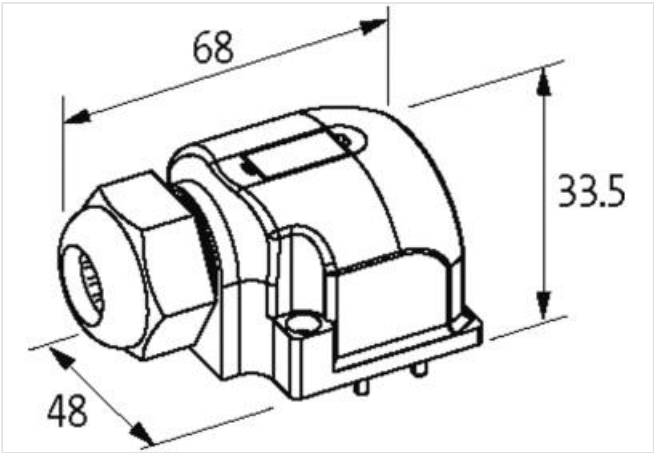

Product may differ from Image

Commercial data	
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440111
ECLASS-10.1	27440111
ECLASS-11.1	27440111

ECLASS-12.0	27440111
ETIM-5.0	EC002585
customs tariff number	85366990
customs tariff number	85369010
customs tariff number	85369010
EAN	4048879058018
EAN	4048879058018
EAN	4048879058018
Packaging unit	1
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Total current max.	8 A
--------------------	-----

Installation

Connection cross section max.	1,5 mm ²
AWG number max.	16

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Mechanical data | Mounting data

Height	33,5 mm
Width	48 mm
Depth	68 mm

Connection type 1

Family construction form	Cap
No. of poles	21