

UFL 20 L PLUG FOR SIGNAL TRANSFER

24 VDC / 1 A - male with LED

Art.No.: 54013

Weight: 0.122

Country of origin: CZ

Model designation: UFL 20 L

Ribbon cable connector + LED



20-pole

Via the combined fixing mechanism, connectors with or without strain relief can be connected.

for plugs with or without strain relief (DIN 41651); for plugs with strain relief, it may be necessary to remove the bottom hook

Link to Product

Illustration

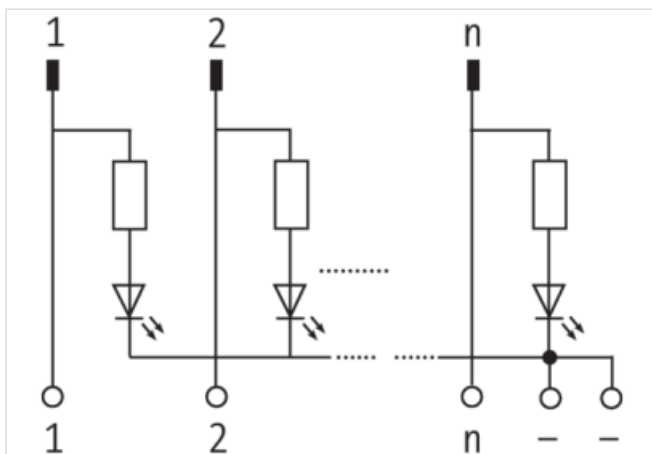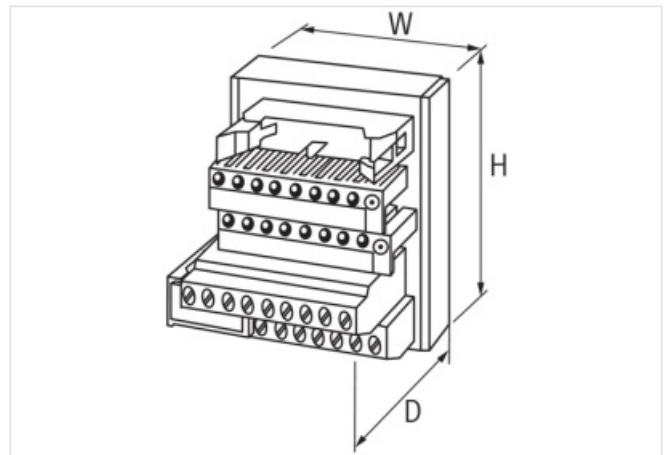

Product may differ from Image



Commercial data

URL Webshop

<https://shop.murrelektronik.com/54013>

GTIN

4048879026604

ECLASS-6.0	27141120
ECLASS-6.1	27141120
ECLASS-7.0	27141120
ECLASS-7.1	27141120
ECLASS-8.0	27141120
ECLASS-8.1	27141120
ECLASS-9.0	27141120
ECLASS-9.1	27141120
ECLASS-10.0.1	27141120
ECLASS-10.1	27141120
ECLASS-11.0	27141120
ECLASS-11.1	27141120
ECLASS-12.0	27141120
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
EAN	4048879026604

Electrical data | Supply

Operating voltage AC	24 V
Operating current max.	1 A

Diagnostics

Status indication LED	red
-----------------------	-----

Device protection | Electrical

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

Mechanical data | Mounting data

Height	63 mm
Width	75 mm
Depth	48 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C