

SV-2 X SUB D 37 -KL. FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Art.No.: 54161

Weight: 0.226

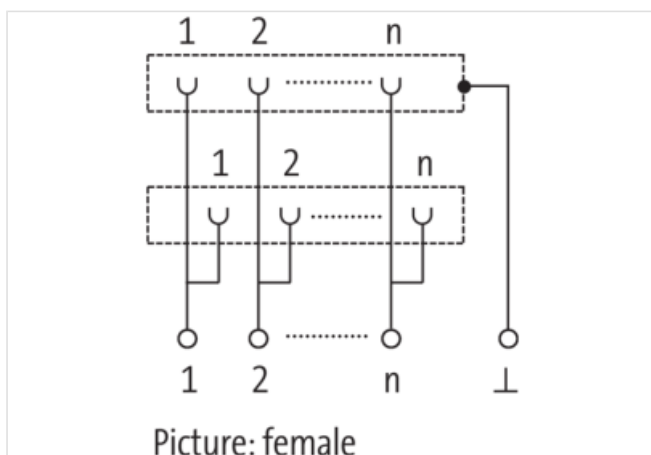
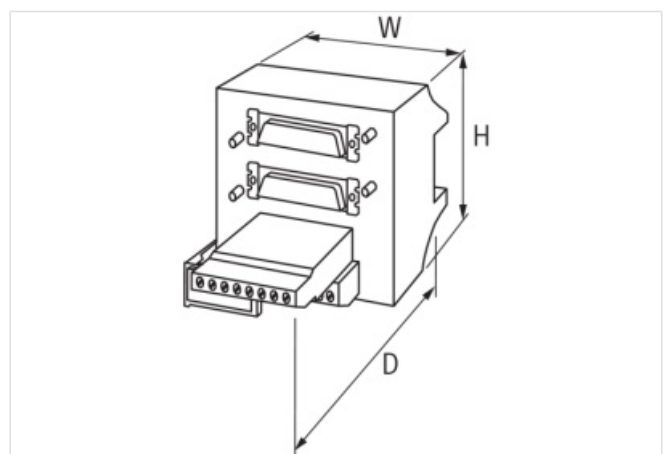
Country of origin: CZ

Model designation: SV-2 X Sub D 37BU-KL.

Female connector

37-pole

Screw terminals

[Link to Product](#)**Illustration**

Product may differ from Image

Header

Material short text SV-2 X Sub D 37BU-KL.

Commercial data

URL Webshop	https://shop.murrelektronik.com/54161
GTIN	4048879026192
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152

ECLASS-7.1	27141152
ECLASS-8.0	27141152
ECLASS-8.1	27141152
ECLASS-9.0	27141152
ECLASS-9.1	27141152
ECLASS-10.0.1	27141152
ECLASS-10.1	27141152
ECLASS-11.0	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ECLASS-13.0	27141152
ECLASS-14.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85366990
EAN	4048879026192
Packaging unit	1

Electrical data | Supply

Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A

Device protection | Electrical

Overvoltage category (EN 60664-1)	I
-----------------------------------	---

Mechanical data | Mounting data

Height	86 mm
Width	90 mm
Depth	78 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C