

PKB 1 FOR SIGNAL TRANSFER

250V / 15 A

Art.No.: 54250

Weight: 0.286

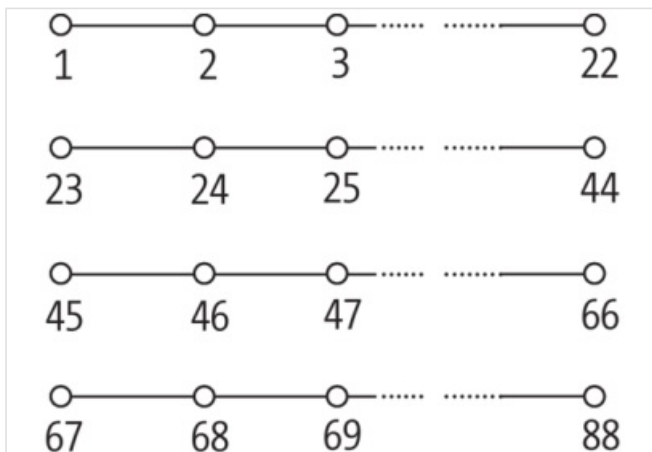
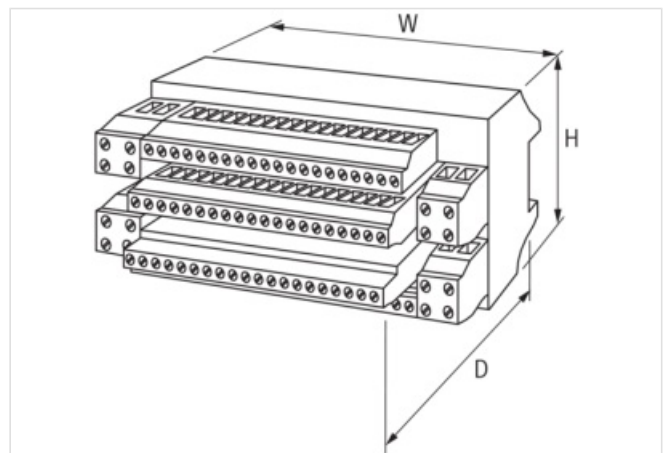
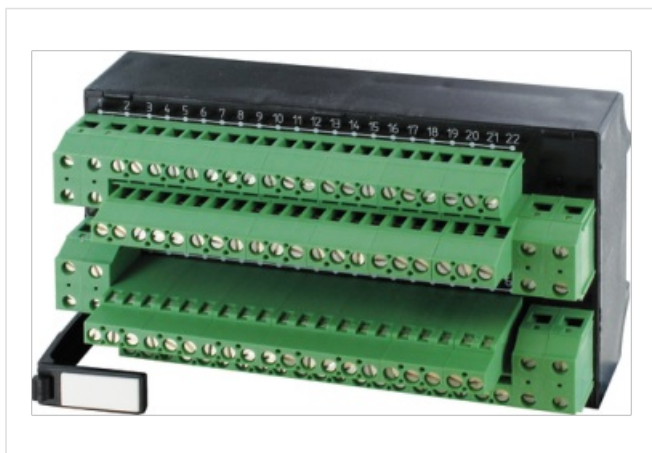
Country of origin: CZ

Model designation: PKB 1

4× 22-pole

15 A per potential rail

Screw plug-in terminals

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/54250
GTIN	4048879026062
ECLASS-6.0	27143424
ECLASS-6.1	27260708

ECLASS-7.0	27141152
ECLASS-7.1	27141152
ECLASS-8.0	27141152
ECLASS-8.1	27141152
ECLASS-9.0	27141152
ECLASS-9.1	27141152
ECLASS-10.0.1	27141152
ECLASS-10.1	27141152
ECLASS-11.0	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ECLASS-13.0	27141152
ECLASS-14.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
EAN	4048879026062

Electrical data | Supply

Operating voltage AC	250 V
----------------------	-------

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Mechanical data | Mounting data

Height	63 mm
Width	140 mm
Depth	48 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C