

PKB 2 FOR SIGNAL TRANSFER

250V / 25 A

Art.No.: 54251

Weight: 0.324

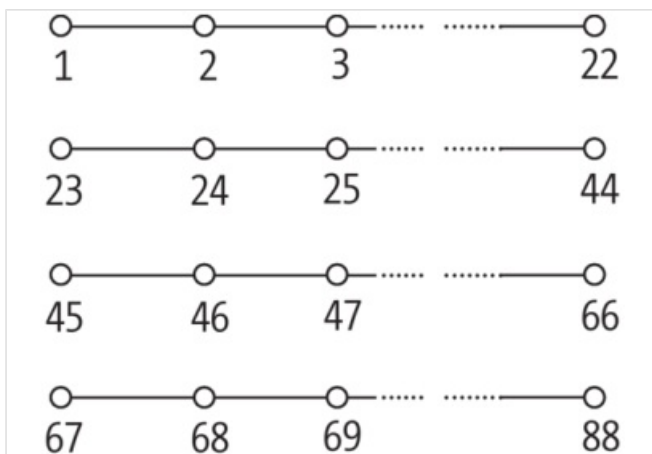
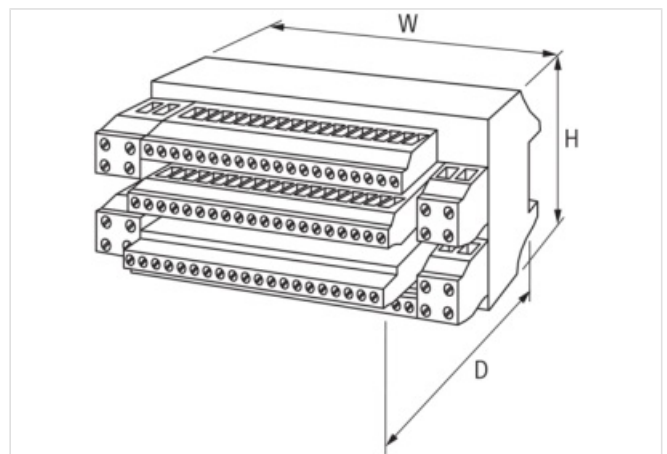
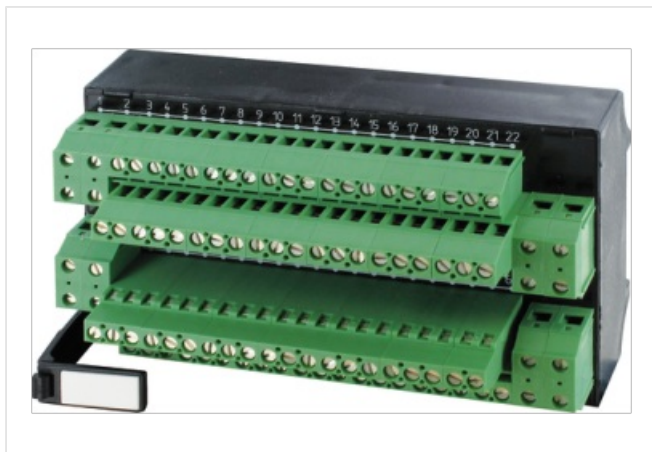
Country of origin: CZ

Model designation: PKB 2

4× 22-pole

25 A per potential rail

Screw plug-in terminals

Input terminal: max. 6 mm² single core, total current: max. 100 A**Link to Product****Illustration**

Product may differ from Image

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/54251>

GTIN

4048879026055

ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-7.1	27141152
ECLASS-8.0	27141152
ECLASS-8.1	27141152
ECLASS-9.0	27141152
ECLASS-9.1	27141152
ECLASS-10.0.1	27141152
ECLASS-10.1	27141152
ECLASS-11.0	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ECLASS-13.0	27141152
ECLASS-14.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
EAN	4048879026055

Electrical data | Supply

Operating voltage AC	250 V
----------------------	-------

Installation

AWG number	9
------------	---

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Mechanical data | Mounting data

Height	75 mm
Width	135 mm
Depth	66 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C