

MASI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to M12 female

Art.No.: 55037

Weight: 0.15

Country of origin: DE

Model designation: MASI67 Umsetzer 2x Profilk.-M12Bu



MASI67 converter

2x profile cable to M12 (female)

Connection cables are in the online shop under "Connection Technology".

[Link to Product](#)

Illustration

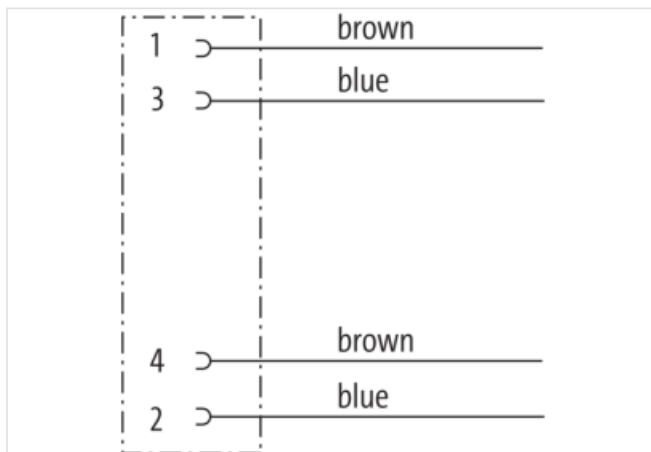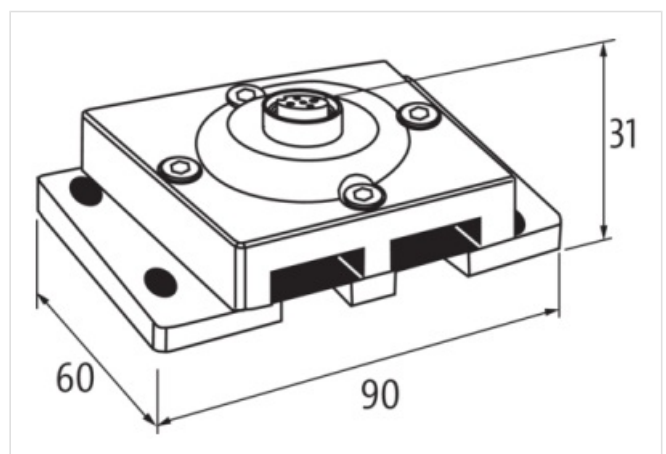

Product may differ from Image



Commercial data

URL Webshop	https://shop.murrelektronik.com/55037
GTIN	4048879052146
ECLASS-6.0	27400209
ECLASS-6.1	27279219

The information in this Product-PDF has been compiled with the utmost care.
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2025-10-05

Murrelektronik GmbH | Grabenstraße 29 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC001583
ETIM-6.0	EC001583
ETIM-7.0	EC001583
ETIM-8.0	EC001583
EAN	4048879052146
customs tariff number	85369010
customs tariff number	85369010
EAN	4048879052146
EAN	4048879052146
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage DC max.	36 V
Total current max.	4 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V

Mechanical data | Mounting data

Height	90 mm
Width	74 mm
Depth	30.5 mm
Mounting method	geschnappt, screwed
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 60664-1
------------------	------------

Connection type 1

Connection type 1	Bus Out
Family construction form	M12
No. of poles	5
Coding	A
Gender	female
Color contact carrier	black
PIN 1	AS-i +
PIN 2	0 V
PIN 3	AS-i -

PIN 4	24 V DC
PIN 5	n.c.