

MAI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to M12 male

Art.No.: 55038

Weight: 0.12

Country of origin: DE

Model designation: MAI67 Umsetzer 2x Profilk.-M12St




MAI67 converter

2x profile cable to M12 (male)

Connection cables are in the online shop under "Connection Technology".

[Link to Product](#)

Illustration

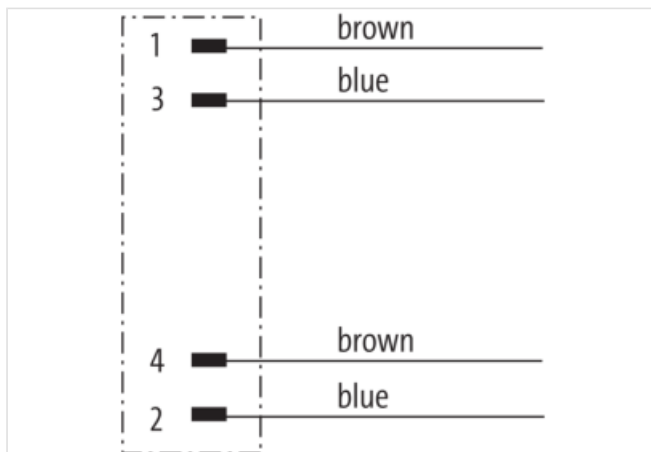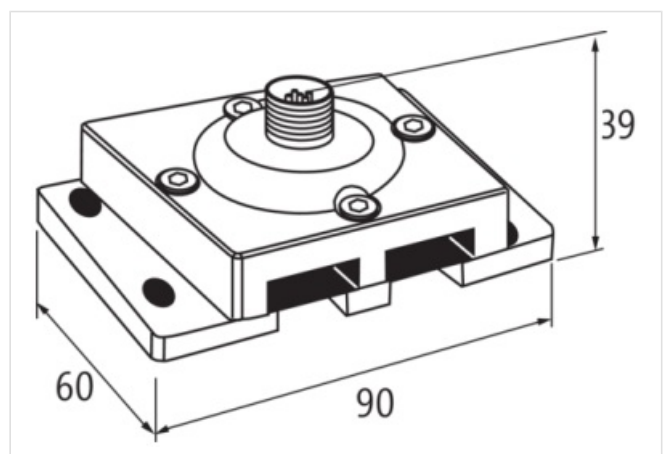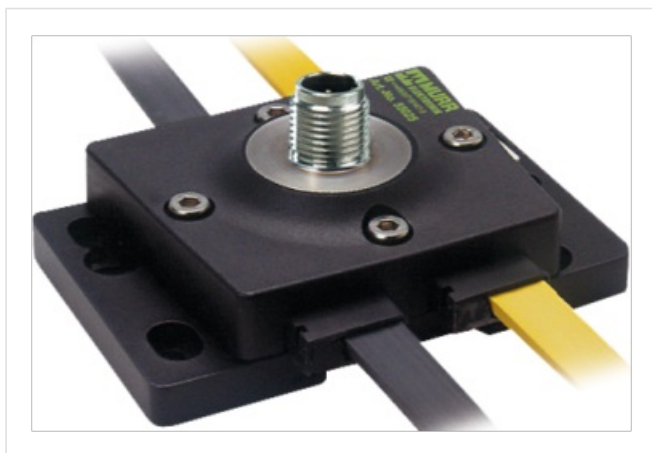

Product may differ from Image



Header

Material short text

MAI67 Umsetzer 2x Profilk.-M12St

Commercial data

URL Webshop

<https://shop.murrelektronik.com/55038>

GTIN	4048879052139
ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-9.1	27440108
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC001583
ETIM-6.0	EC001583
ETIM-7.0	EC001583
ETIM-8.0	EC001583
customs tariff number	85366990
EAN	4048879052139
Packaging unit	1

Electrical data | Supply

Operating voltage DC max.	36 V
Total current max.	4 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V

Mechanical data | Mounting data

Height	90 mm
Width	74 mm
Depth	39 mm
Mounting method	geschnappt, screwed
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN IEC 60664-1
------------------	----------------

Connection type 1

Connection type 1	Bus In
Family construction form	M12
No. of poles	5
Coding	A
Gender	male
Color contact carrier	Black
PIN 1	AS-i +
PIN 2	0 V
PIN 3	AS-i -

PIN 4	24 V DC
PIN 5	n.c.