

POTENTIAL TERMINAL BLOCK YE BLUE YE BLUE

Art.No.: 56080
Weight: 0.079
Country of origin: CZ
Model designation: Potenzialkbl. gelb blau gelb blau


Potential terminal block
yellow/blue/yellow/blue

Link to Product

Illustration



Product may differ from Image

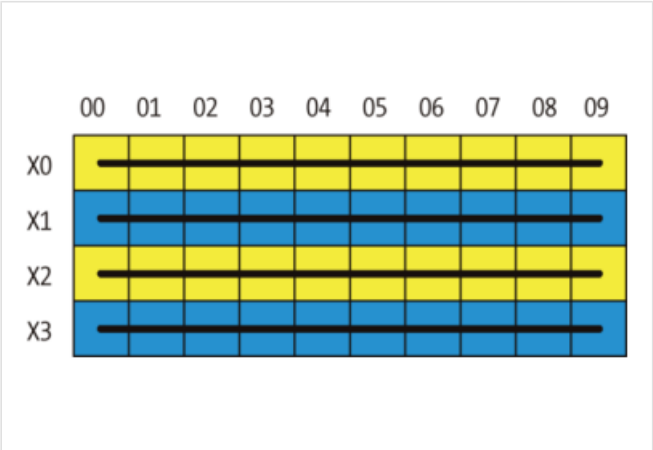

Header

Material short text Potenzialkbl. gelb blau gelb blau

Commercial data

URL Webshop	https://shop.murrelektronik.com/56080
GTIN	4048879049443
ECLASS-6.0	27141106
ECLASS-6.1	27141106
ECLASS-7.0	27141106
ECLASS-7.1	27141106
ECLASS-8.0	27141106
ECLASS-8.1	27141106
ECLASS-9.0	27141106
ECLASS-9.1	27141106
ECLASS-10.0.1	27141106
ECLASS-10.1	27141106
ECLASS-11.0	27141106
ECLASS-11.1	27141106
ECLASS-12.0	27141106
ECLASS-13.0	27141106
ECLASS-14.0	27141106
ETIM-5.0	EC001283
ETIM-6.0	EC001283

ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85369010
EAN	4048879049443
Packaging unit	1

Electrical data | Supply

Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Total current max.	10 A

Installation

Connection cross section max.	2.5 mm ²
AWG number min.	28
AWG number max.	14

Installation | Connection

Connection	Spring clamp plug-in terminals
------------	--------------------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

Mechanical data | Mounting data

Height	70 mm
Width	56 mm
Depth	32.5 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C