

## EUROCARD HOLDER

SKP 64/IB

Art.No.: 63042

Weight: 0.362

Country of origin: CZ

Model designation: SKP 64/IB(a,b)

Screw terminals

64-pole B (EN 60603)

Row a, b


With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.

The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

### [Link to Product](#)

#### Illustration

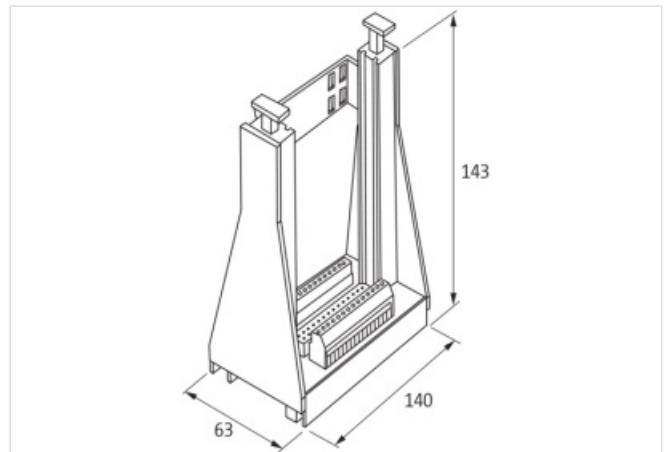

Product may differ from Image



#### Header

Material short text SKP 64/IB(a,b)

**Commercial data**

|                       |                                                                                           |
|-----------------------|-------------------------------------------------------------------------------------------|
| URL Webshop           | <a href="https://shop.murrelektronik.com/63042">https://shop.murrelektronik.com/63042</a> |
| GTIN                  | 4048879042093                                                                             |
| ECLASS-6.0            | 27260710                                                                                  |
| ECLASS-6.1            | 27260704                                                                                  |
| ECLASS-7.0            | 27440402                                                                                  |
| ECLASS-7.1            | 27440402                                                                                  |
| ECLASS-8.0            | 27440402                                                                                  |
| ECLASS-8.1            | 27440402                                                                                  |
| ECLASS-9.0            | 27460201                                                                                  |
| ECLASS-9.1            | 27440402                                                                                  |
| ECLASS-10.0.1         | 27440402                                                                                  |
| ECLASS-10.1           | 27440402                                                                                  |
| ECLASS-11.0           | 27460201                                                                                  |
| ECLASS-11.1           | 27460201                                                                                  |
| ECLASS-12.0           | 27460201                                                                                  |
| ECLASS-13.0           | 27460201                                                                                  |
| ECLASS-14.0           | 27460201                                                                                  |
| ETIM-5.0              | EC002780                                                                                  |
| ETIM-6.0              | EC002780                                                                                  |
| ETIM-7.0              | EC002780                                                                                  |
| ETIM-8.0              | EC002780                                                                                  |
| customs tariff number | 85366990                                                                                  |
| EAN                   | 4048879042093                                                                             |
| Packaging unit        | 1                                                                                         |

**Electrical data | Supply**

|                        |       |
|------------------------|-------|
| Operating voltage AC   | 250 V |
| Operating current max. | 2 A   |

**Installation**

|                                     |                   |
|-------------------------------------|-------------------|
| Connection cross-section solid max. | 4 mm <sup>2</sup> |
|-------------------------------------|-------------------|

**Installation | Pin assignment**

|              |    |
|--------------|----|
| No. of poles | 64 |
|--------------|----|

**Device protection | Electrical**

|                                   |   |
|-----------------------------------|---|
| Overvoltage category (EN 60664-1) | I |
|-----------------------------------|---|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data**

|                          |              |
|--------------------------|--------------|
| Type of socket connector | B (EN 60603) |
|--------------------------|--------------|

**Mechanical data | Material data**

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

**Mechanical data | Mounting data**

|                            |                           |
|----------------------------|---------------------------|
| Height                     | 137 mm                    |
| Width                      | 63 mm                     |
| Depth                      | 170 mm                    |
| Mounting method            | geschnappt, screwed       |
| Suitable for mounting type | (EN 60715), mounting rail |