

MKS - D 20/1300-1 M DIODE MODULES

Mounting rail / screw-type terminal

Art.No.: 67052

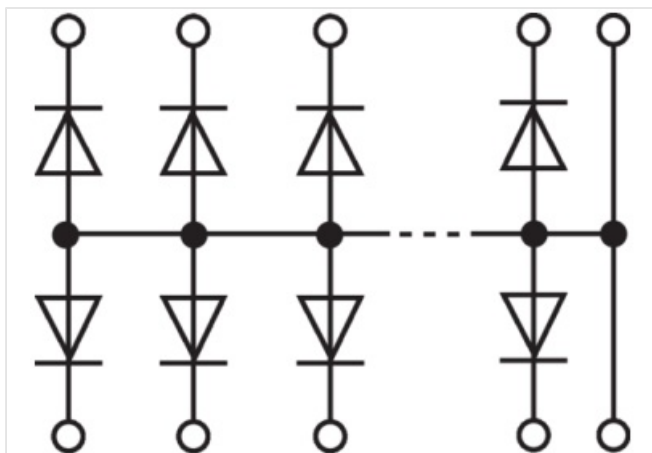
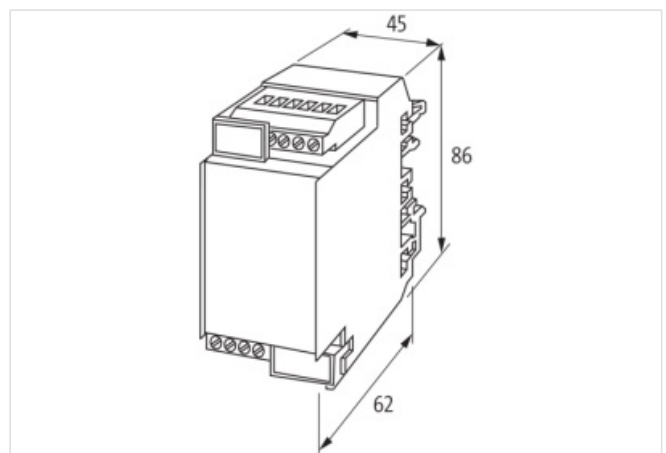
Weight: 0.106

Country of origin: CZ

Model designation: MKS - D 20/1300-1 M

20 diodes

Common potential anode

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

MKS - D 20/1300-1 M

Commercial data

URL Webshop

<https://shop.murrelektronik.com/67052>

GTIN

4048879041928

ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-7.1	27371010
ECLASS-8.0	27371010
ECLASS-8.1	27371010
ECLASS-9.0	27371010
ECLASS-9.1	27371010
ECLASS-10.0.1	27371010
ECLASS-10.1	27371010
ECLASS-11.0	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010
ECLASS-13.0	27371010
ECLASS-14.0	27371010
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
customs tariff number	85411000
EAN	4048879041928
Packaging unit	1

Electrical data | Supply

Operating voltage AC max.	48 V
Operating voltage DC max.	48 V

Mechanical data | Mounting data

Height	86 mm
Width	45 mm
Depth	62 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Family construction form	terminal
No. of poles	22
Gender	female
Connection	Screw terminals SK