

MKS/BCD-1300 DIODE MODULES

Mounting rail / screw-type terminal

Art.No.: 67079

Weight: 0.131

Country of origin: CZ



Model designation: MKS/BCD-1300

Universal diode 1 300 V, 1 A

Diode logic for converting hexadecimal to binary numbers

[Link to Product](#)

Illustration

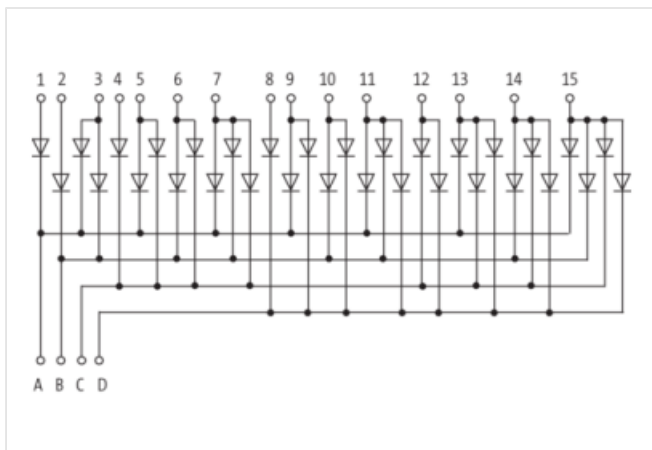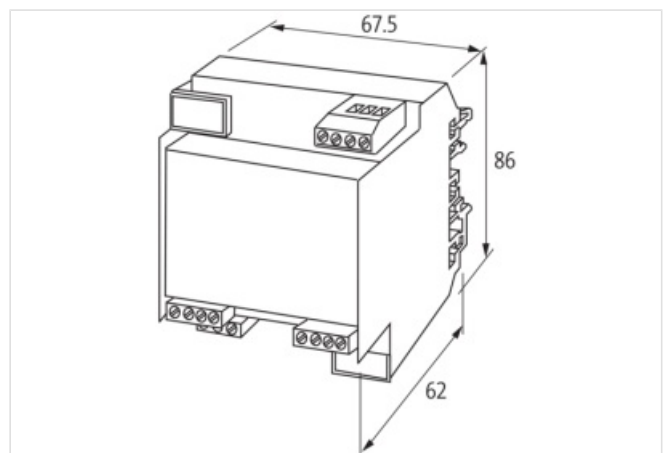

Product may differ from Image



Header

Material short text MKS/BCD-1300

Commercial data

URL Webshop <https://shop.murrelektronik.com/67079>

GTIN 4048879041829

ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-7.1	27371010
ECLASS-8.0	27371010
ECLASS-8.1	27371010
ECLASS-9.0	27371010
ECLASS-9.1	27371010
ECLASS-10.0.1	27371010
ECLASS-10.1	27371010
ECLASS-11.0	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010
ECLASS-13.0	27371010
ECLASS-14.0	27371010
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
customs tariff number	85411000
EAN	4048879041829
Packaging unit	1

Mechanical data | Mounting data

Height	86 mm
Width	67.5 mm
Depth	62 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 2

Family construction form	terminal
No. of poles	4
Gender	female
Connection	Screw terminals SK
PIN 1	D
PIN 2	C
PIN 3	B
PIN 4	A
Family construction form	terminal
No. of poles	15
Gender	female
Connection	Screw terminals SK