

**ASSEMBLY MODULE MKS - M 4**

Mounting rail / screw-type terminal

Art.No.: 67081

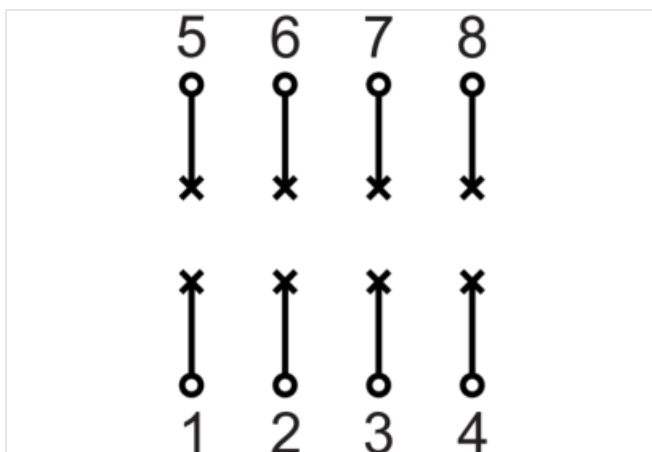
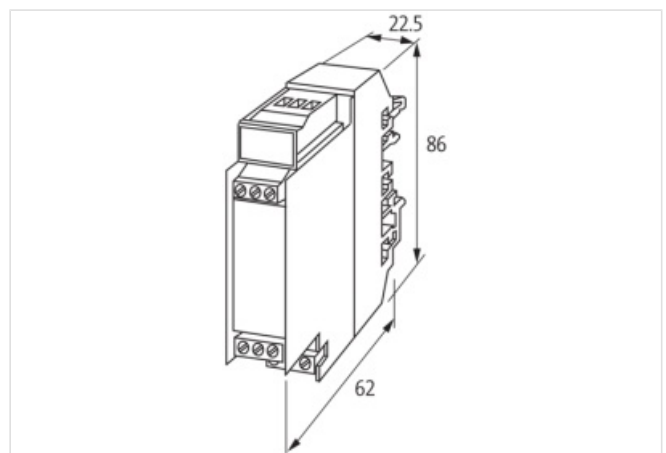
Weight: 0.052

Country of origin: CZ

Model designation: MKS - M 4

4 pairs of solder pins

screw terminals connected to solder pin pairs

**Link to Product****Illustration**

Product may differ from Image

**Header**

Material short text

MKS - M 4

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/67081>

GTIN

4048879041812

|                       |               |
|-----------------------|---------------|
| ECLASS-6.0            | 27379201      |
| ECLASS-6.1            | 27141149      |
| ECLASS-7.0            | 27141149      |
| ECLASS-7.1            | 27141149      |
| ECLASS-8.0            | 27141149      |
| ECLASS-8.1            | 27141149      |
| ECLASS-9.0            | 27141149      |
| ECLASS-9.1            | 27141149      |
| ECLASS-10.0.1         | 27141149      |
| ECLASS-10.1           | 27141149      |
| ECLASS-11.0           | 27141149      |
| ECLASS-11.1           | 27141149      |
| ECLASS-12.0           | 27141149      |
| ETIM-5.0              | EC002780      |
| ETIM-6.0              | EC002780      |
| ETIM-7.0              | EC002780      |
| ETIM-8.0              | EC002780      |
| customs tariff number | 85369010      |
| EAN                   | 4048879041812 |
| Packaging unit        | 1             |

**Electrical data | Supply**

|                           |       |
|---------------------------|-------|
| Operating voltage AC max. | 250 V |
| Operating voltage DC max. | 250 V |
| Operating current max.    | 2.5 A |

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                    |                 |
|--------------------|-----------------|
| Material housing   | Plastic         |
| Housing properties | removable cover |

**Mechanical data | Mounting data**

|                            |                                     |
|----------------------------|-------------------------------------|
| Height                     | 68 mm                               |
| Width                      | 22.5 mm                             |
| Depth                      | 65 mm                               |
| Mounting method            | geschnappt                          |
| Suitable for mounting type | Mounting rail TH35, (EN 60715), G32 |
| Distance of solder pins    | 30 mm                               |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |

**Connection type 1**

|                          |                    |
|--------------------------|--------------------|
| Family construction form | terminal           |
| No. of poles             | 8                  |
| Gender                   | female             |
| Connection               | Screw terminals SK |