

ASSEMBLY MODULE MKS - M 8

Mounting rail / screw-type terminal

Art.No.: 67083

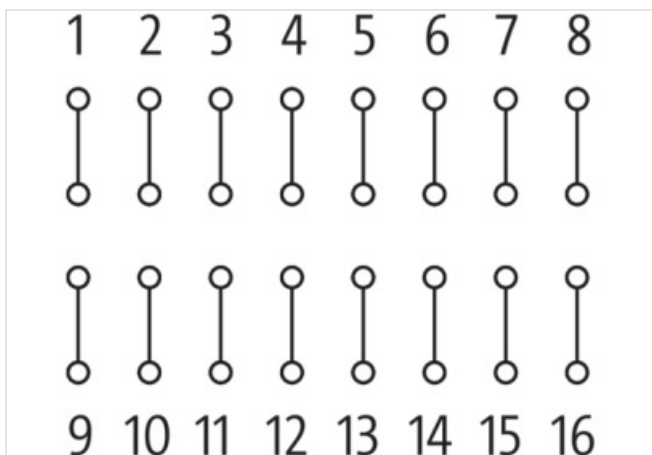
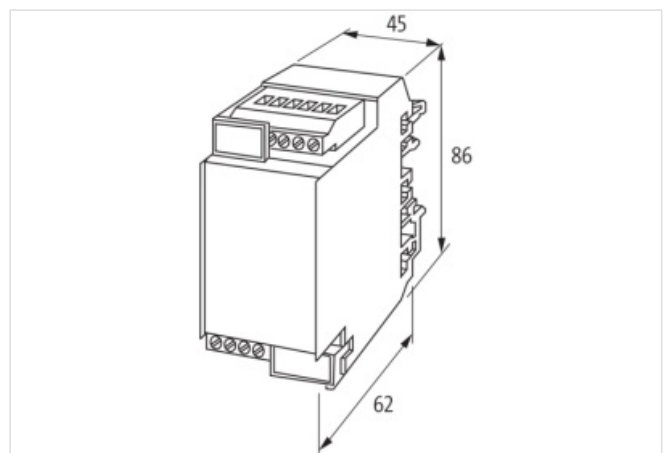
Weight: 0.086

Country of origin: CZ

Model designation: MKS - M 8

8 pairs of solder pins

screw terminals connected to solder pin pairs

Link to Product**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/67083
GTIN	4048879041805
ECLASS-6.0	27379201
ECLASS-6.1	27141149

ECLASS-7.0	27141149
ECLASS-7.1	27141149
ECLASS-8.0	27141149
ECLASS-8.1	27141149
ECLASS-9.0	27141149
ECLASS-9.1	27141149
ECLASS-10.0.1	27141149
ECLASS-10.1	27141149
ECLASS-11.0	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
EAN	4048879041805

Electrical data | Supply

Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	5 A

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Housing properties	removable cover

Mechanical data | Mounting data

Height	86 mm
Width	45 mm
Depth	62 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32
Distance of solder pins	40 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Family construction form	terminal
No. of poles	16
Gender	female
Connection	Screw terminals SK