



M12 MALE ON REAR OF MSUD VALVE PLUG FORM B 10 MM

Art.No.: 7000-41921-0000000
Weight: 0.031
Country of origin: CZ
Model designation: MSNL0-C-W


Form B (10 mm) – M12, connector at the rear
max. 125 V AC/DC
without components
3-pole
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

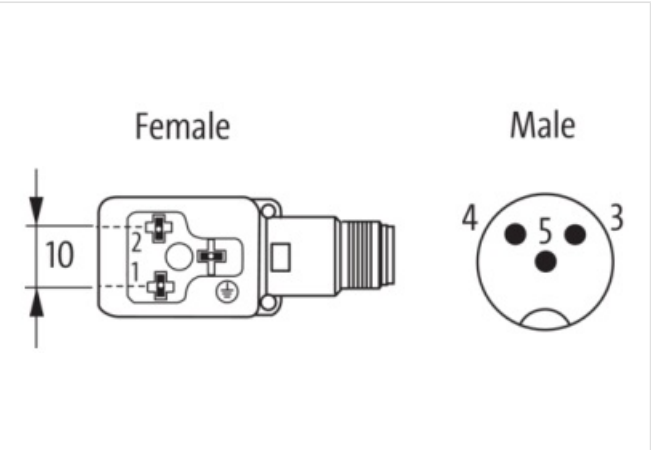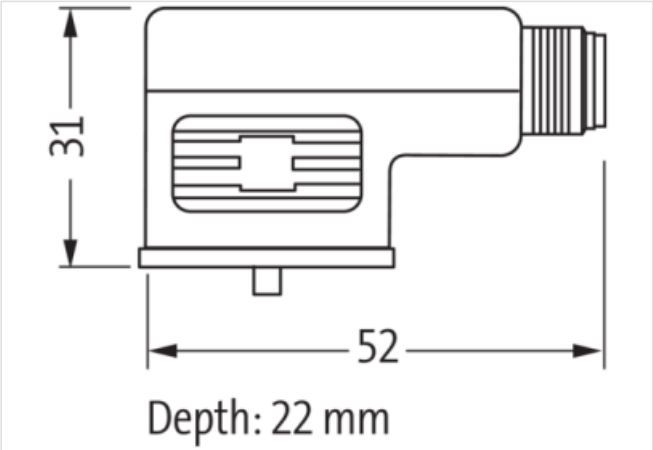

Product may differ from Image

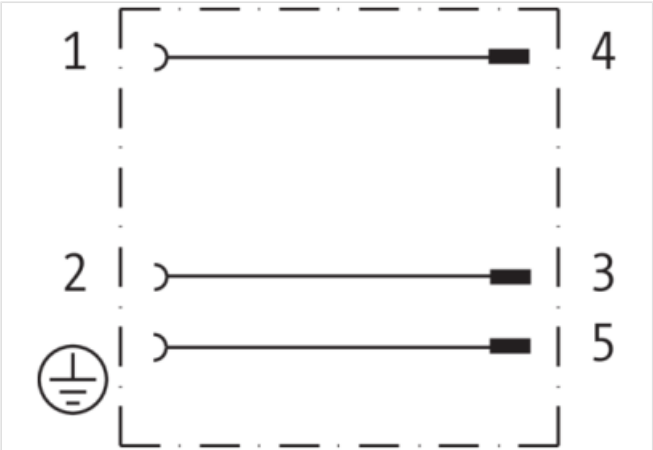

Side 1	
Family construction form	MSUD
Mounting method	inserted, screwed

Tightening torque 0.4 Nm

Side 2

Family construction form M12
 Coding A
 Mounting method inserted, screwed
 Tightening torque 0.6 Nm

Commercial data

URL Webshop <https://shop.murrelektronik.com/7000-41921-0000000>
 EAN 4048879143387

Electrical data | Supply

Operating voltage AC max. 125 V
 Operating voltage DC max. 125 V
 Current operating per contact max. 4 A

Diagnostics

Status indication LED no

Installation | Connection

Mounting set M3

Installation | Pin assignment

No. of poles PE

Device protection | Electrical

Degree of protection (EN IEC 60529) IP67
 Additional condition protection degree inserted, screwed
 Pollution Degree 3
 Rated surge voltage 1.5 kV
 Material group (IEC 60664-1) I

Mechanical data | Material data

Locking material Steel
 Coating locking galvanized

Environmental characteristics | Climatic

Operating temperature min. -25 °C
 Operating temperature max. 85 °C

Important installation notes

Note on bending radius **Attention:** Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
 Note on strain relief Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.