




MODL.VARIO insert for coupling housing type B

8-pole M12, female, shielded
Art.No.: 7000-48116-0000000
Weight: 0.04
Country of origin: DE
Model designation: MSB_ADB-A-08D

Insert - mobile housing
Female straight – male straight
M12, 8-pole
A-coded

Link to Product

Illustration

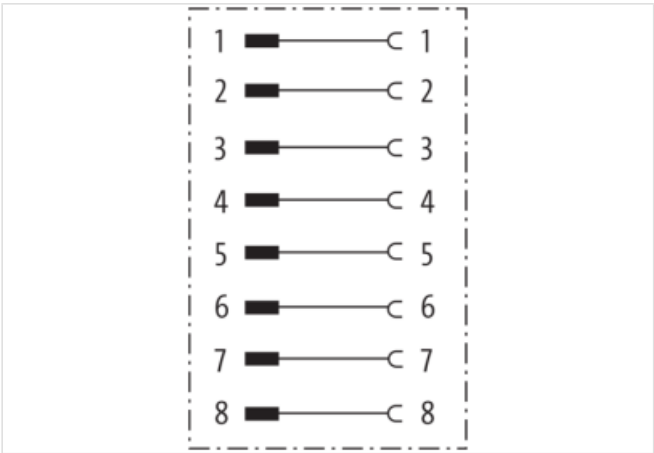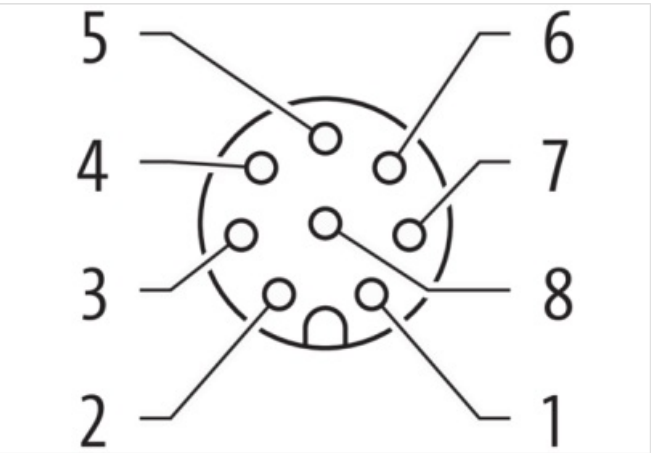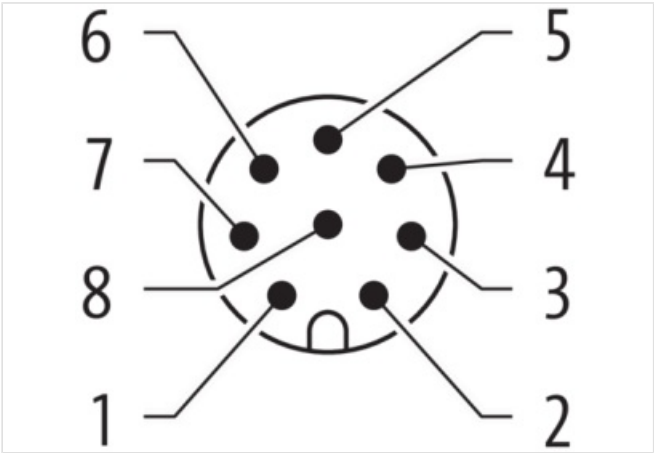

Product may differ from Image

Side 1	
Family construction form	M12
Coding	A
Side 2	
Family construction form	M12
Coding	A
Commercial data	
URL Webshop	https://shop.murrelektronik.com/7000-48116-0000000

GTIN	4048879576543
ECLASS-6.0	27279221
ECLASS-6.1	27279221
ECLASS-7.0	27440104
ECLASS-7.1	27440104
ECLASS-8.0	27440104
ECLASS-8.1	27440104
ECLASS-9.0	27440106
ECLASS-9.1	27440106
ECLASS-10.0.1	27440106
ECLASS-10.1	27440106
ECLASS-11.0	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
ECLASS-13.0	27440106
ECLASS-14.0	27440106
ETIM-5.0	EC001855
ETIM-6.0	EC001855
ETIM-7.0	EC001855
ETIM-8.0	EC001855
EAN	4048879576543

Electrical data | Supply

Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Current operating per contact max.	2 A

Installation | Connection

Tightening torque	0.6 Nm
Mounting set	M12 x 1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67, IP65
Additional condition protection degree	inserted, screwed
Rated surge voltage	0.8 kV
Rated insulation voltage	800 V

Mechanical data | Material data

Material housing	Brass
Coating housing	nickel plated
Material gasket	FKM

Mechanical data | Mounting data

Mounting method	inserted, screwed, Shaking protection
-----------------	---------------------------------------

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	85 °C