

**CABLE GLAND MS M20X 1.5**

Art.No.: 7000-91001-0102000  
Weight: 0.034  
Country of origin: DE  
Model designation: Kabelverschraubung MS M20X1,5


Cable compression gland  
M20 x 1.5  
metric  
2x pin connector 26pol gray  
(conduit on request)  
Quantity: 100 pcs.

**Link to Product**

**Illustration**



Product may differ from Image

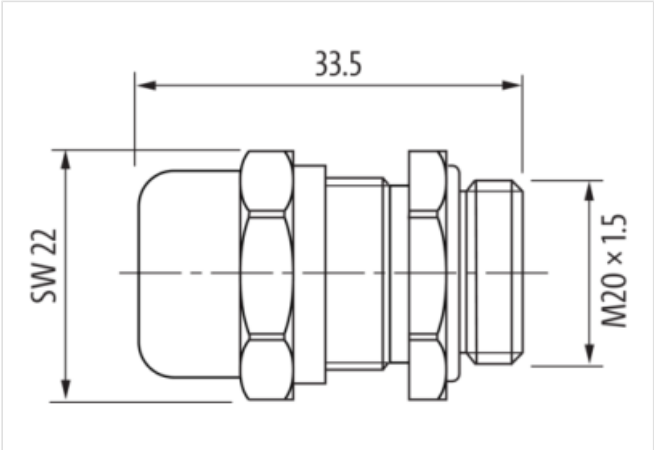

**Commercial data**

|               |                                                                                                                     |
|---------------|---------------------------------------------------------------------------------------------------------------------|
| URL Webshop   | <a href="https://shop.murrelektronik.com/7000-91001-0102000">https://shop.murrelektronik.com/7000-91001-0102000</a> |
| GTIN          | 4048879468497                                                                                                       |
| ECLASS-6.0    | 27279221                                                                                                            |
| ECLASS-6.1    | 27149109                                                                                                            |
| ECLASS-7.0    | 27149109                                                                                                            |
| ECLASS-7.1    | 27149109                                                                                                            |
| ECLASS-8.0    | 27149109                                                                                                            |
| ECLASS-8.1    | 27149109                                                                                                            |
| ECLASS-9.0    | 27140801                                                                                                            |
| ECLASS-9.1    | 27144432                                                                                                            |
| ECLASS-10.0.1 | 27144432                                                                                                            |
| ECLASS-10.1   | 27144432                                                                                                            |
| ECLASS-11.0   | 27144432                                                                                                            |
| ECLASS-11.1   | 27144432                                                                                                            |
| ECLASS-12.0   | 27140801                                                                                                            |
| ECLASS-13.0   | 27140801                                                                                                            |
| ECLASS-14.0   | 27140801                                                                                                            |
| ETIM-5.0      | EC001855                                                                                                            |
| ETIM-6.0      | EC001855                                                                                                            |
| ETIM-7.0      | EC001855                                                                                                            |
| ETIM-8.0      | EC001855                                                                                                            |
| EAN           | 4048879468497                                                                                                       |

**Mechanical data | Mounting data**

|                     |       |
|---------------------|-------|
| Clamping range min. | 9 mm  |
| Clamping range max. | 13 mm |