

M12 male 90° B-cod. screw terminal shielded2-pol., max. 0.75mm², 6 - 8mm, shielded

Art.No.: 7000-14015-0000000

Weight: 0.06

Country of origin: DE

Model designation: M12 Ste.gew.2pol.B-Code gesch.Schraubkl.

PROFIBUS

Male 90°

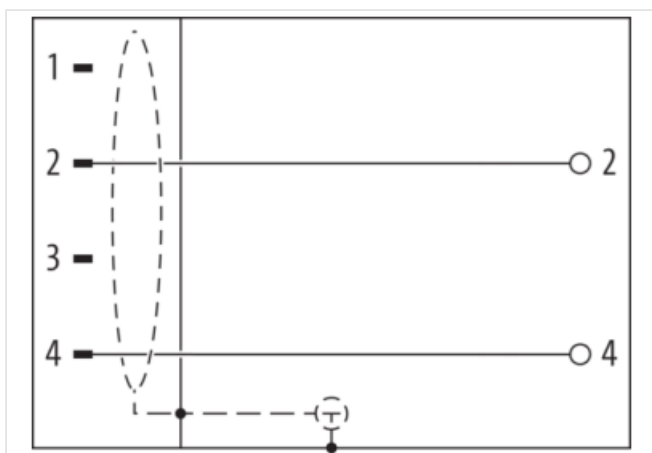
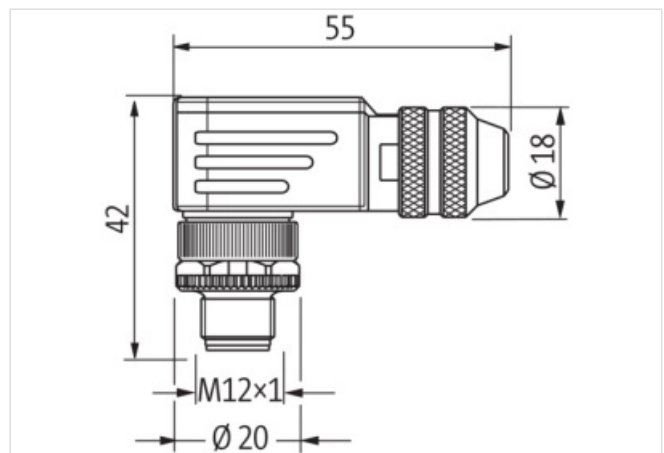
M12, 2-pole

B-coded

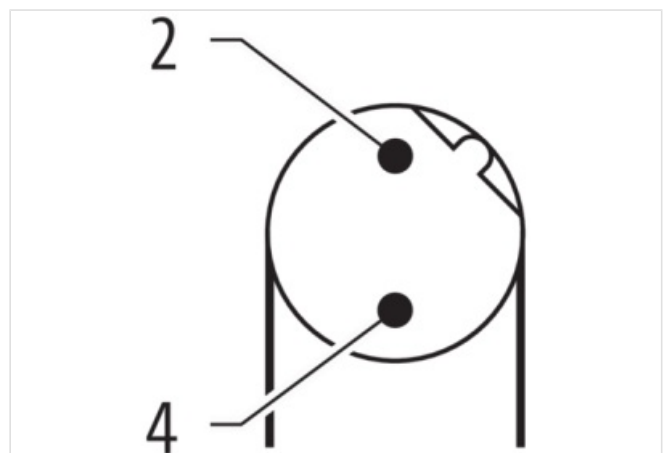
shielded

Sealing range (cable Ø): 6...8 mm

Screw terminals

[Link to Product](#)**Illustration**

Product may differ from Image

**Side 1**

Family construction form M12

Degree of protection (EN IEC 60529) IP67

Commercial dataURL Webshop <https://shop.murrelektronik.com/7000-14015-0000000>

customs tariff number	85366990
EAN	4048879419154
Packaging unit	1
Electrical data Supply	
Operating voltage AC max.	60 V
Operating voltage DC max.	60 V
Current operating per contact max.	4 A
Installation	
Connection cross section max.	0.75 mm ²
Device protection Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data Material data	
Material housing	Brass
Coating housing	nickel plated
Mechanical data Mounting data	
Clamping range min.	6 mm
Clamping range max.	8 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C
Important installation notes	
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.