

SVS VALVE PLUG FORM BI 11MM FIELD-WIREABLE

0...230V M16x1.5

Art.No.: 7000-30001-0000000

Weight: 0.05

Country of origin: CN

Model designation: MSVS-KB5K-M16

Form BI (11 mm)

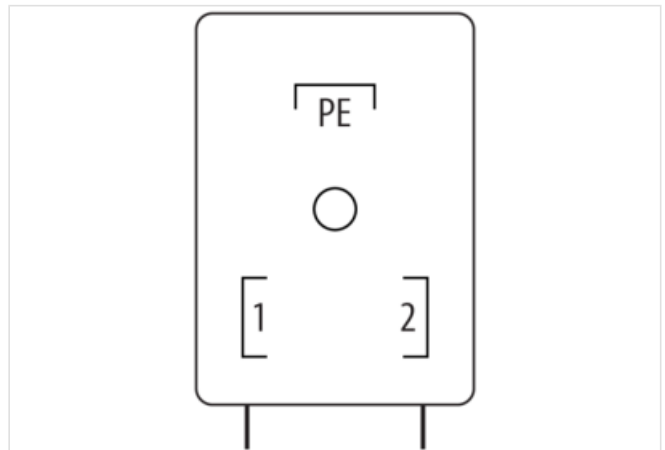
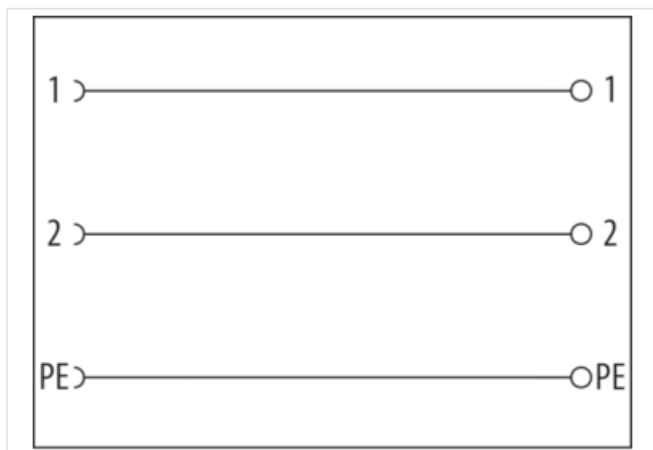
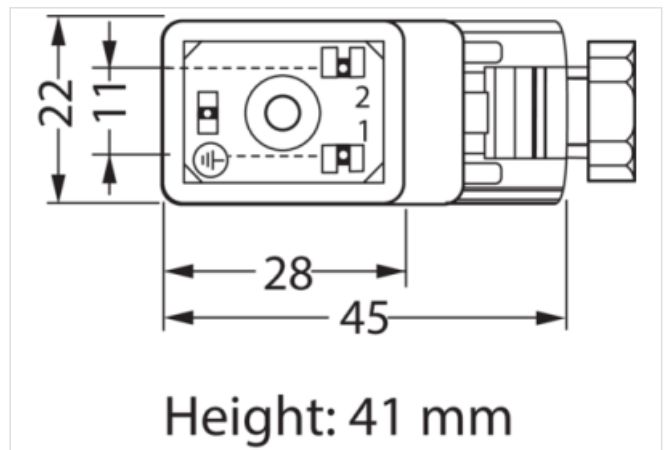
max. 230 V AC/DC

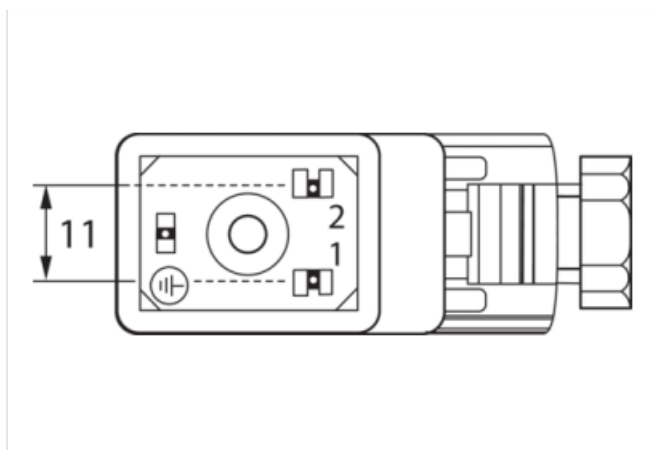
without components

metric

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**



Product may differ from Image

**Side 1**

Degree of protection (EN IEC 60529) IP65

Commercial data

URL Webshop	https://shop.murrelektronik.com/7000-30001-0000000
customs tariff number	85366990
EAN	4048879187053
Packaging unit	1

Electrical data | Supply

Operating voltage AC	230 V
Operating voltage AC min.	207 V
Operating voltage AC max.	253 V
Operating voltage DC	230 V
Operating voltage DC min.	207 V
Operating voltage DC max.	253 V
Current operating per contact max.	10 A

InstallationConnection cross section max. 1.5 mm²**Installation | Connection**

Tightening torque	0.4 Nm
Mounting set	M16 x 1.5

Device protection | Electrical

Additional condition protection degree locked, with screw connection, inserted

Mechanical data | Mounting data

Fastening screw	M3x31
Clamping range min.	5 mm
Clamping range max.	10 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Important installation notes

Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.