

Adaptor M12 male back/MSUD valve plug A-18mm 180°

5-pol. A-cod.

Art.No.: 7000-41445-0000000

Weight: 0.03

Country of origin: CZ

Model designation: MSZLI-C 180°

Form A (18 mm) – M12, connector at the rear

for pressure switches

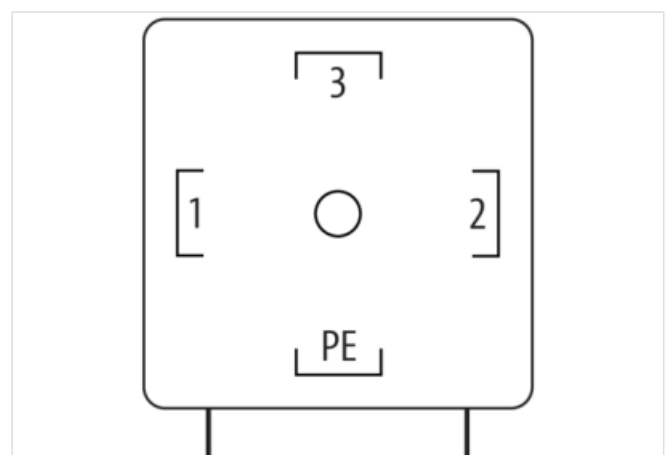
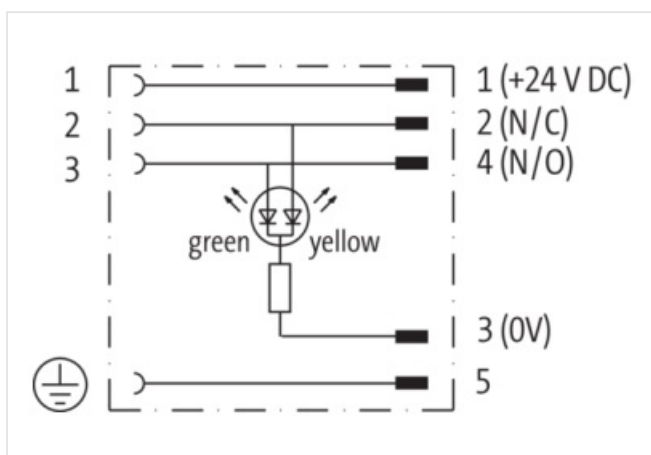
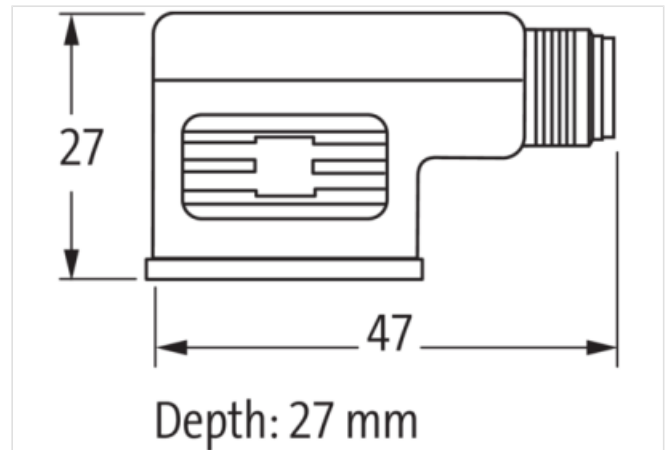
24 V DC $\pm 25\%$

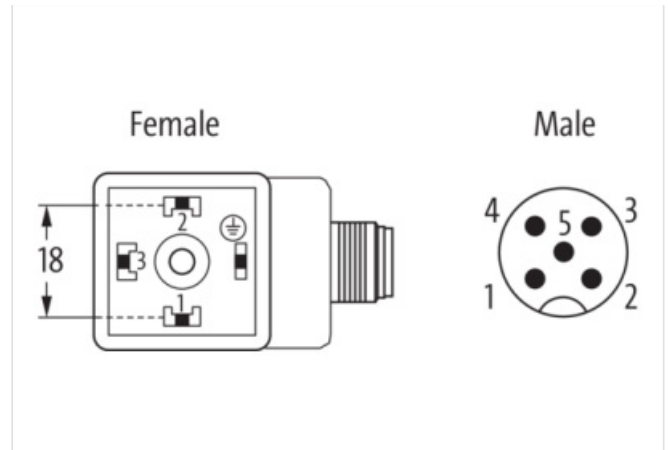
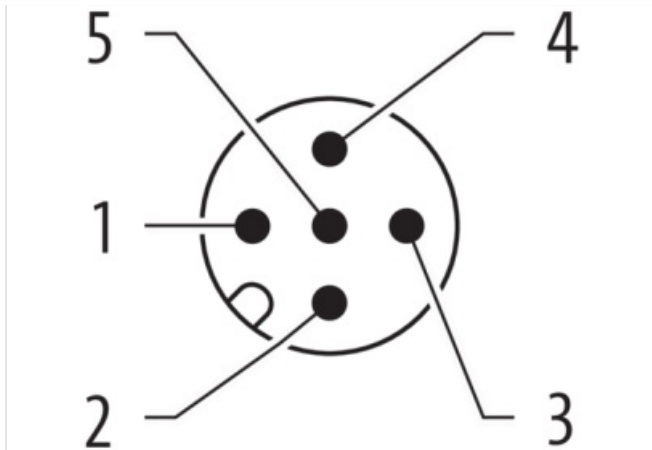
LED (yellow/green)

5-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**



Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/7000-41445-0000000
customs tariff number	85366990
EAN	4048879596145
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	18 V
Operating voltage DC max.	30 V
Current operating per contact max.	4 A

Installation | Connection

Tightening torque	0.4 Nm
Mounting set	M3x31

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	90 °C

Important installation notes

Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.