

M12 MALE ON TOP OF MSUD VALVE PLUG FORM BI 11MM

Art.No.: 7000-41981-0000000

Weight: 0.03

Country of origin: CZ

Model designation: MSLL0-A-W

Form BI (11 mm) – M12, connector top entry

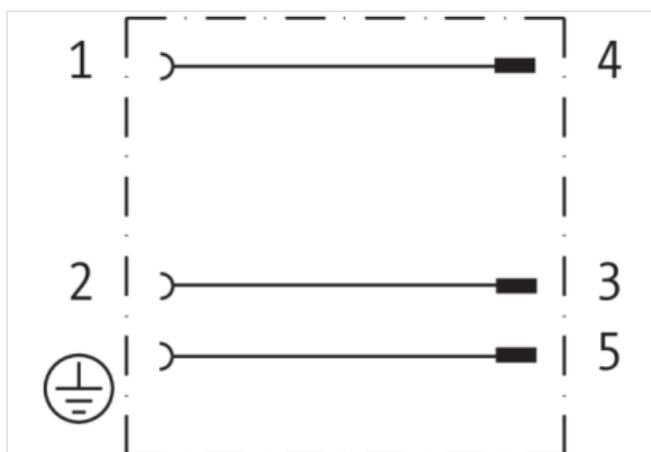
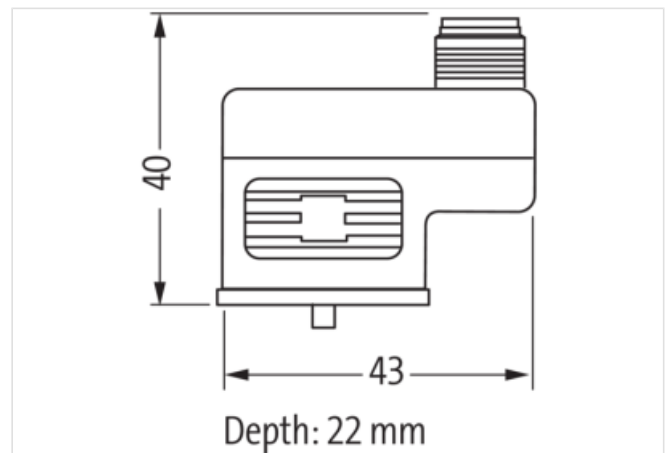
max. 125 V AC/DC

without components

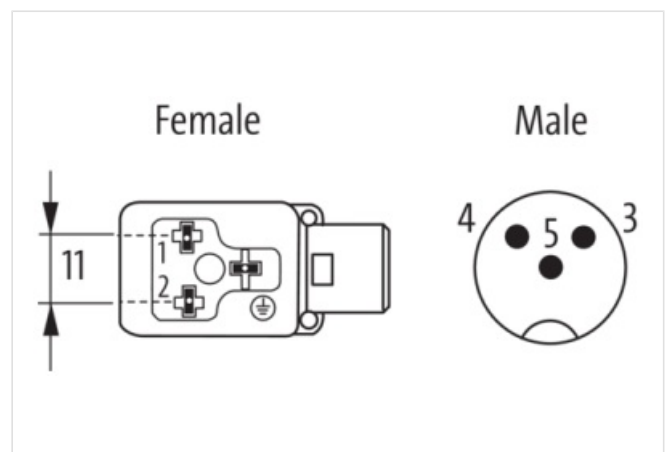
3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Side 1**

Family construction form	MSUD
Tightening torque	0.4 Nm

Side 2	
Family construction form	M12
Tightening torque	0.6 Nm
Commercial data	
URL Webshop	https://shop.murrelektronik.com/7000-41981-0000000
customs tariff number	85366990
EAN	4048879143325
Packaging unit	1
Electrical data Supply	
Operating voltage AC max.	125 V
Operating voltage DC max.	125 V
Current operating per contact max.	4 A
Installation Connection	
Mounting set	M3x31
Installation Pin assignment	
No. of poles	PE
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C
Important installation notes	
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.