

Adaptor M12 male / M12 female A-cod. 3xLED

5-pol.

Art.No.: 7000-42281-0000000

Weight: 0.019

Country of origin: DE

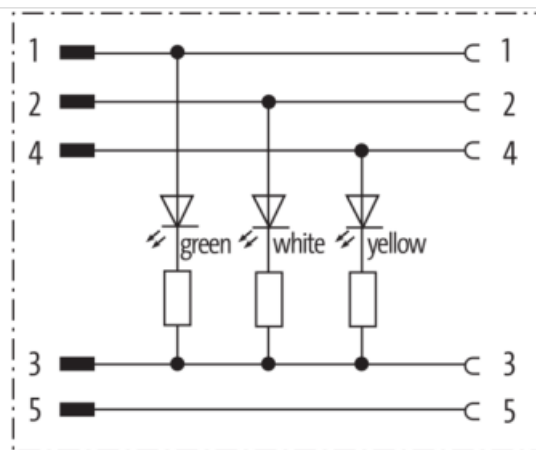
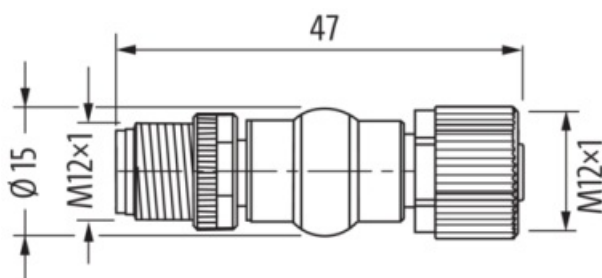
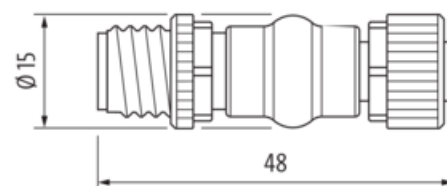
Model designation: MSB04L2-A-U

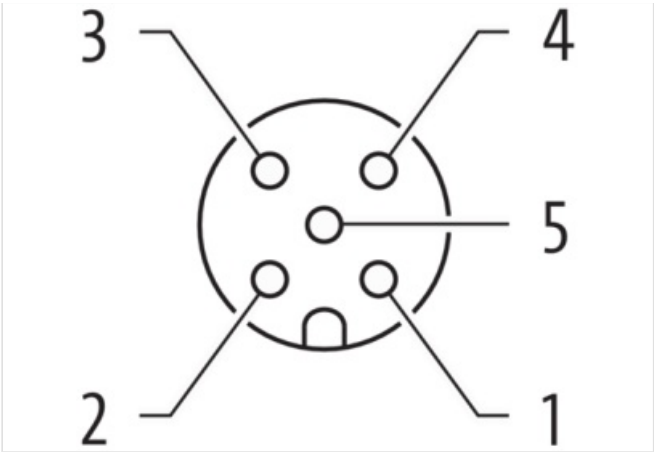
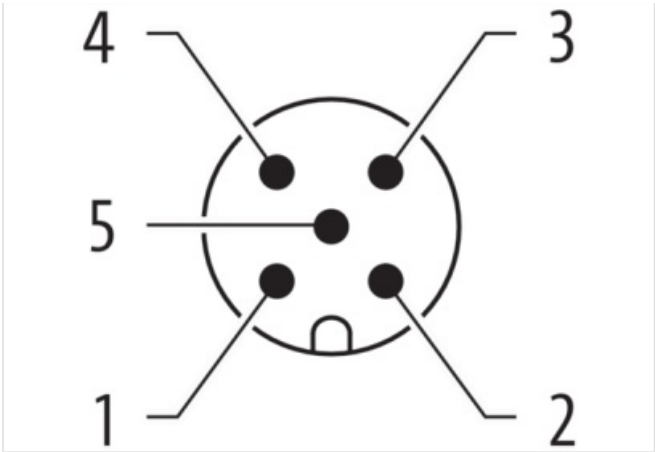
Adapter

Male - female

M12 – M12, 5-pole

3× LED (PNP)

[Link to Product](#)**Illustration**



Product may differ from Image



Commercial data	
URL Webshop	https://shop.murrelektronik.com/7000-42281-0000000
customs tariff number	85366990
EAN	4048879415996
Packaging unit	1
Electrical data Supply	
Operating voltage DC max.	30 V
Current operating per contact max.	4 A
Operating voltage DC max. (UL-listed)	30 V
Installation Connection	
Tightening torque	0.6 Nm
Mounting set	M12 x 1
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Rated insulation voltage	800 V
Mechanical data Material data	
Material housing	PUR
Locking material	Zinc die-casting
Coating locking	Nickeled
Mechanical data Mounting data	
Mounting method	inserted, screwed, Shaking protection
Environmental characteristics Climatic	
Operating temperature min.	-30 °C
Operating temperature max.	85 °C
Important installation notes	
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.