




7/8"-BULKHEAD FLANGE PLUG 5 POLE

Art.No.: 7000-50111-0000000
Weight: 0.12
Country of origin: CZ
Model designation: MSCBSV-CA-U

Control cabinet entry system
Female - male
7/8" (5-pole)

Link to Product

Illustration

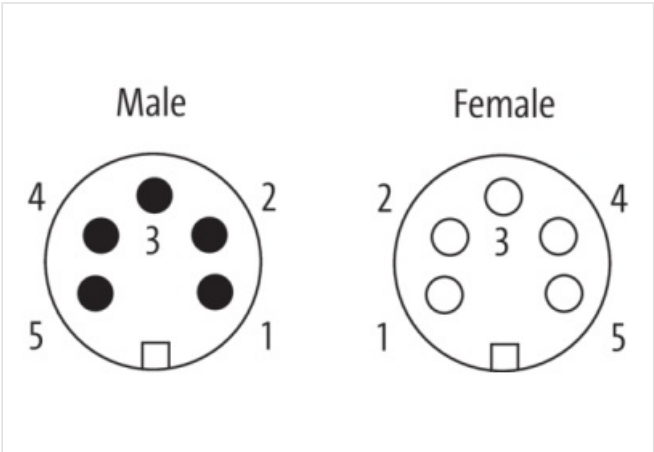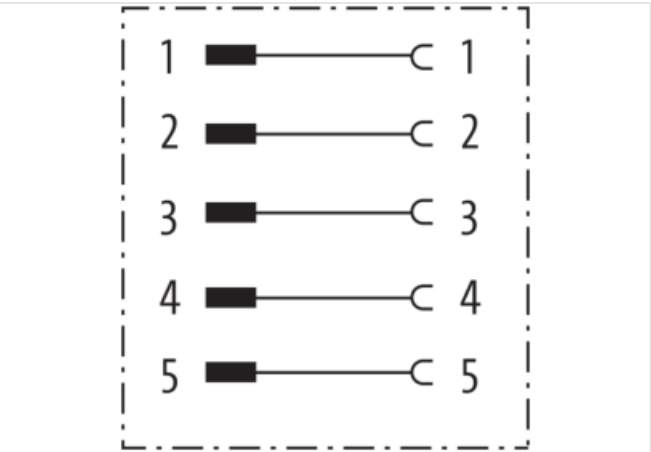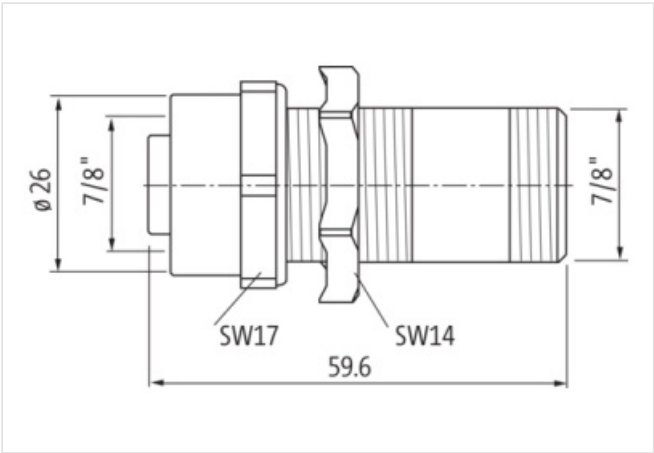

Product may differ from Image

Header	
Material short text	MSCBSV-CA-U
Side 1	
Family construction form	7/8"
Commercial data	
URL Webshop	https://shop.murrelektronik.com/7000-50111-0000000
GTIN	4048879138123
ECLASS-6.0	27279220
ECLASS-6.1	27279220
ECLASS-7.0	27440103

ECLASS-7.1	27440103
ECLASS-8.0	27440103
ECLASS-8.1	27440103
ECLASS-9.0	27440109
ECLASS-9.1	27440109
ECLASS-10.0.1	27440109
ECLASS-10.1	27440109
ECLASS-11.0	27440109
ECLASS-11.1	27440109
ECLASS-12.0	27440109
ECLASS-13.0	27440109
ECLASS-14.0	27440109
ETIM-5.0	EC002635
ETIM-6.0	EC002635
ETIM-7.0	EC002635
ETIM-8.0	EC002635
customs tariff number	85366990
EAN	4048879138123
Packaging unit	1

Electrical data | Supply

Current operating per contact max.	12 A
Current phase - neutral	230 V
Current phase - phase	400 V

Installation | Connection

Tightening torque	1.5 Nm
Mounting set	7/8"

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Pollution Degree	3
Rated surge voltage	3 kV
Material group (IEC 60664-1)	I

Mechanical data | Mounting data

Mounting method	inserted, screwed, Shaking protection
-----------------	---------------------------------------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Important installation notes

Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.