

CABLE GLAND PA M16X 1.5

Art.No.: 7000-91001-0001600

Weight: 0.006

Country of origin: DE

Model designation: Kabelverschraubung PA M16X1,5

Cable compression gland

M16 x 1.5

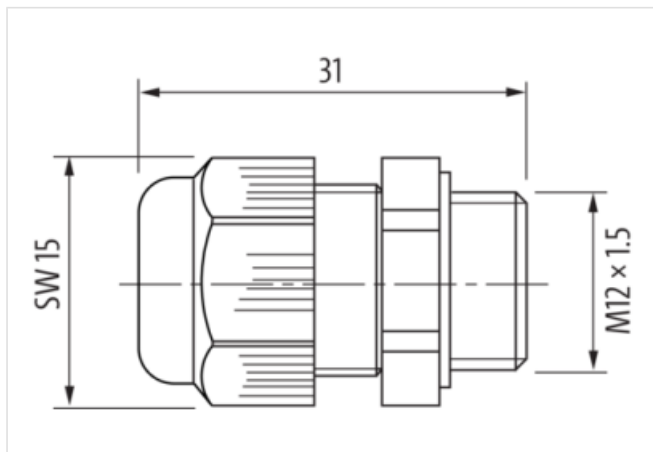
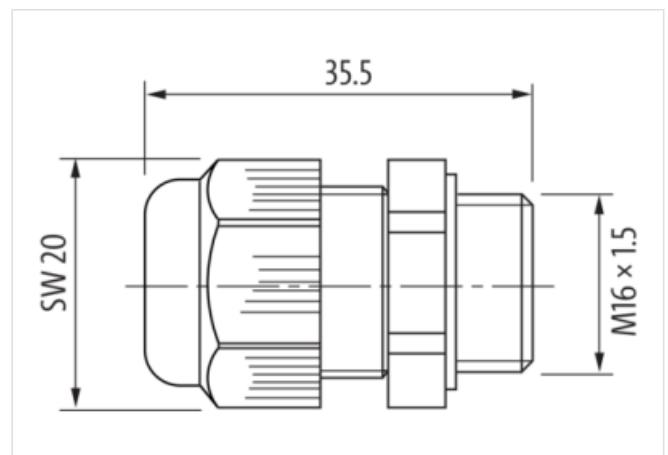
metric

(gray)

2x pin connector 26pol gray

(conduit on request)

Quantity: 100 pcs.

Link to Product**Illustration**

Product may differ from Image

Header

Material short text

Kabelverschraubung PA M16X1,5

Commercial dataURL Webshop <https://shop.murrelektronik.com/7000-91001-0001600>

GTIN 4048879468251

ECLASS-6.0 27279221

ECLASS-6.1 27149109

ECLASS-7.0	27149109
ECLASS-7.1	27149109
ECLASS-8.0	27149109
ECLASS-8.1	27149109
ECLASS-9.0	27140801
ECLASS-9.1	27144432
ECLASS-10.0.1	27144432
ECLASS-10.1	27144432
ECLASS-11.0	27144432
ECLASS-11.1	27144432
ECLASS-12.0	27140801
ECLASS-13.0	27140801
ECLASS-14.0	27140801
ETIM-5.0	EC001855
ETIM-6.0	EC001855
ETIM-7.0	EC001855
ETIM-8.0	EC001855
customs tariff number	39174000
EAN	4048879468251
Packaging unit	100

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP68
-------------------------------------	------

Mechanical data | Material data

Material housing	PA
Material gasket	NBR

Mechanical data | Mounting data

Height	35.5 mm
Width	15 mm
Depth	15 mm
Clamping range min.	5 mm
Clamping range max.	10 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	100 °C
Additional condition temperature range	depending on cable quality