

**EXACT12 SAFETY, FIX. CABLE, P1-4 M12 5POLE LED,**

P5-8 M12 4/3-pol 1:1 no LED, 10m PUR/PVC

Art.No.: 8000-98710-4071000

Weight: 1.9

Country of origin: DE

Model designation: MVP12N-AN8F407 10.0m

PUR/PVC

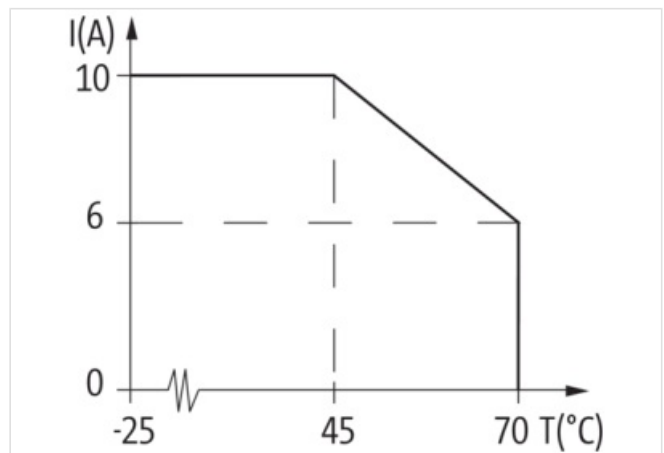
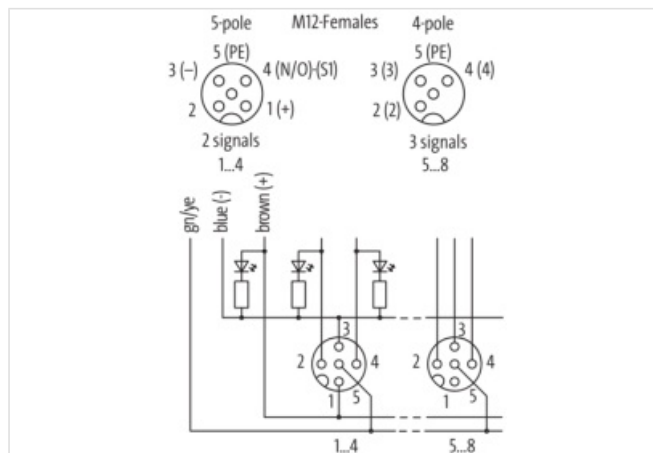
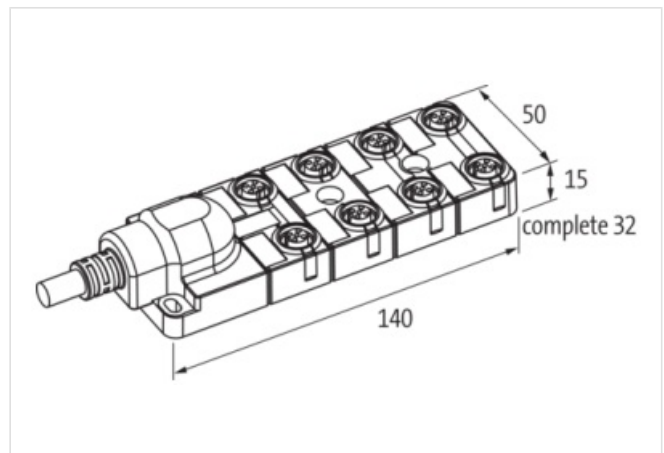
10.0 m

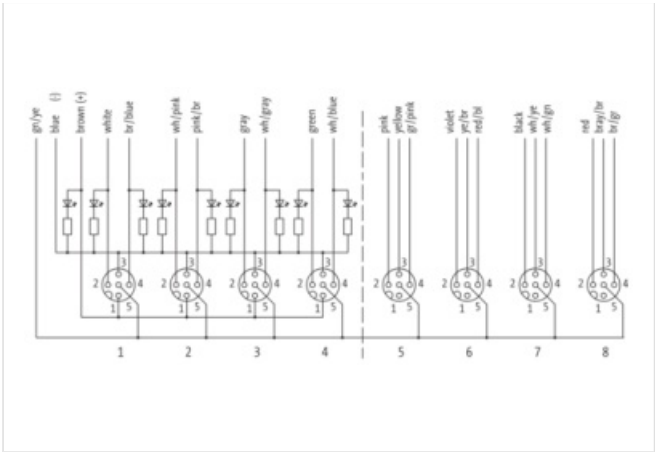
4-/3-pole

Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**



Product may differ from Image



| Commercial data                     |                                                                                                                     |
|-------------------------------------|---------------------------------------------------------------------------------------------------------------------|
| URL Webshop                         | <a href="https://shop.murrelektronik.com/8000-98710-4071000">https://shop.murrelektronik.com/8000-98710-4071000</a> |
| GTIN                                | 4048879053556                                                                                                       |
| ECLASS-6.0                          | 27143423                                                                                                            |
| ECLASS-6.1                          | 27279219                                                                                                            |
| ECLASS-7.0                          | 27279219                                                                                                            |
| ECLASS-7.1                          | 27279219                                                                                                            |
| ECLASS-8.0                          | 27279219                                                                                                            |
| ECLASS-8.1                          | 27279219                                                                                                            |
| ECLASS-9.0                          | 27440108                                                                                                            |
| ECLASS-9.1                          | 27440108                                                                                                            |
| ECLASS-10.0.1                       | 27440108                                                                                                            |
| ECLASS-10.1                         | 27440108                                                                                                            |
| ECLASS-11.0                         | 27440108                                                                                                            |
| ECLASS-11.1                         | 27440108                                                                                                            |
| ECLASS-12.0                         | 27440108                                                                                                            |
| ECLASS-13.0                         | 27440108                                                                                                            |
| ECLASS-14.0                         | 27440108                                                                                                            |
| ETIM-5.0                            | EC002585                                                                                                            |
| ETIM-6.0                            | EC002585                                                                                                            |
| ETIM-7.0                            | EC002585                                                                                                            |
| ETIM-8.0                            | EC002585                                                                                                            |
| EAN                                 | 4048879053556                                                                                                       |
| Electrical data   Supply            |                                                                                                                     |
| Operating voltage DC                | 24 V                                                                                                                |
| Current operating per contact max.  | 4 A                                                                                                                 |
| Installation   Connection           |                                                                                                                     |
| Mounting set                        | M12 x 1                                                                                                             |
| Device protection   Electrical      |                                                                                                                     |
| Degree of protection (EN IEC 60529) | IP67, IP65                                                                                                          |
| Device protection   Media           |                                                                                                                     |
| Flame resistance                    | flame retardant                                                                                                     |
| Mechanical data   Material data     |                                                                                                                     |

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

**Mechanical data | Mounting data**

|                 |                |
|-----------------|----------------|
| Mounting method | Schraubgewinde |
|-----------------|----------------|

**Environmental characteristics | Climatic**

|                                        |                            |
|----------------------------------------|----------------------------|
| Operating temperature min.             | -20 °C                     |
| Operating temperature max.             | 60 °C                      |
| Additional condition temperature range | depending on cable quality |

**Connection type 3**

|                          |                |
|--------------------------|----------------|
| Family construction form | free cable end |
| No. of poles             | 23             |
| Family construction form | M12            |
| No. of poles             | 4              |
| Coding                   | A              |
| Gender                   | female         |
| Color contact carrier    | yellow         |
| PIN 1                    | n.c.           |
| PIN 2                    | 2              |
| PIN 3                    | 3              |
| PIN 4                    | 4              |
| PIN 5                    | PE             |
| Family construction form | M12            |
| No. of poles             | 5              |
| Coding                   | A              |
| Gender                   | female         |
| Color contact carrier    | black          |
| PIN 1                    | +              |
| PIN 2                    | NC S 2         |
| PIN 3                    | -              |
| PIN 4                    | NO S 1         |
| PIN 5                    | PE             |