




Black caps -plastic-

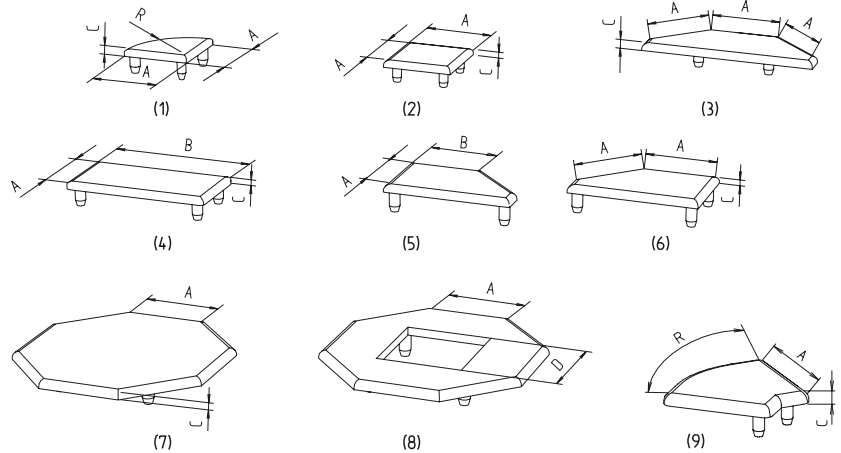

Black RAL 9005

Code No.	Type	lot sizes	Version	See figure	A	B	C	D	R
Black plastic cap									
4000421	F-G/GG/2G/3G 30x30	10, 20, 30... pcs		2	30	–	3	–	–
4010421	F-G/GG/2G/3G 40x40	10, 20, 30... pcs		2	40	–	4	–	–
4030421	F-G/GG 40x80	10, 20, 30... pcs		4	40	80	4	–	–
4088421	SP-50x50, F-G/GG/2G/3G 50x50	10, 20, 30... pcs		2	50	–	4	–	–
4100421	F-R 30	10, 20, 30... pcs		1	30		3		R 29
4121421	F-G/GG/2G/3G 60x60	10, 20, 30... pcs		2	60	–	4	–	–
4040421	F-G/GG/2G 80x80	10, 20, 30... pcs		2	80	–	4	–	–
4388421	15x40	10, 20, 30... pcs		4	15	40	4	–	–
4348421	15x60	10, 20, 30... pcs		4	15	60	4	–	–
4358421	15x80	10, 20, 30... pcs		4	15	80	4	–	–
4368421	15x120	10, 20, 30... pcs		4	15	120	4	–	–
4378421	15x160	10, 20, 30... pcs		4	15	160	4	–	–
4158421	2x40	10, 20, 30... pcs		5	40	–	4	–	–
4158422	2x40	10, 20, 30... pcs		6	40	–	4	–	–
4258421	3x40	10, 20, 30... pcs		3	40	–	4	–	–
4050421	8x40	10, 20, 30... pcs		7	40	–	4	–	–
4050422	8x40	–		8	40	–	4	40	–
4200421	KL 30x30, ESP 30	10, 20, 30... pcs		2	30	–	3	–	–
4600421	KLD 30x30	10, 20, 30... pcs		2	30	–	3	–	–
4700421	KLE 30x30	10, 20, 30... pcs		2	30	–	3	–	–
4408421	KLW 30-15	10, 20, 30... pcs		9	30	–	3	–	15°
4418421	W/KLW 30-30	10, 20, 30... pcs		9	30	–	3	–	30°
4428421	W/KLW 30-45	10, 20, 30... pcs		9	30	–	3	–	45°
4448421	W/KLW 30-60	10, 20, 30... pcs		9	30	–	3	–	60°
4438421	W/KLW 30-90	10, 20, 30... pcs		9	30	–	3	–	90°
4210421	KL 40x40, ESP 40	10, 20, 30... pcs		2	40	–	4	–	–
4610421	KLD 40x40	10, 20, 30... pcs		2	40	–	4	–	–
4710421	KLE 40x40	10, 20, 30... pcs		2	40	–	4	–	–
4458421	KLW 40-15	10, 20, 30... pcs		9	40	–	4	–	15°
4468421	W/KLW 40-30	10, 20, 30... pcs		9	40	–	4	–	30°
4478421	W/KLW 40-45	10, 20, 30... pcs		9	40	–	4	–	45°
4498421	W/KLW 40-60	10, 20, 30... pcs		9	40	–	4	–	60°
4488421	W/KLW 40-90	10, 20, 30... pcs		9	40	–	4	–	90°