

NPT Thread Convertors Enlargers, Reducers and Convertors





Features

- Suitable for use in Zone 1, 2, 21, 22 Exd & Exe
- Available in unplated Brass, Nickel Plated Brass and Stainless Steel 316

Certification & Standards

Approved to:	EN/IEC 60079-0, 60079-1, 60079-7, 60079-31
EC TYPE Examination Certificate:	IMQ 13ATEX016X, IECEx IMQ 13.0005X
	Ex d IIC Gb
	Ex e IIC Gb
	Ex tb IIIC Db
	Class I Div. 1 ABCD, Class II Div. 1 EFG (does not include M16 & 3/8" NPT or unplated brass products)
	Approved to UL1203
	Approved to CSA C22.2 Nr. 60079-04 and 60079-1

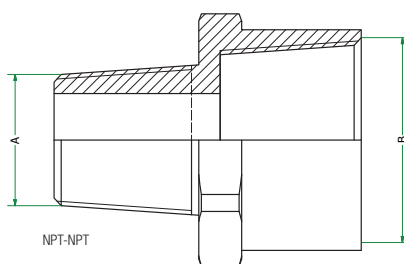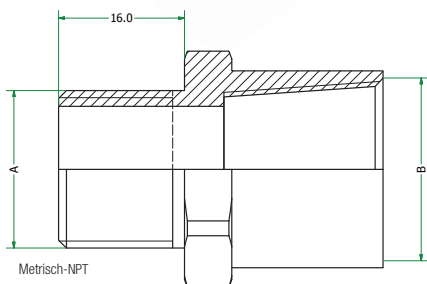

Male External Thread (A)	NPT-Female Internal Thread (B)							
	NPT 1/2	NPT 3/4	NPT 1	NPT 1 1/4	NPT 1 1/2	NPT 2	NPT 2 1/2	NPT 3
M16	EXN/M16-050/TC	–	–	–	–	–	–	–
M20	EXN/M20-050/TC	EXN/M20-075/TC	–	–	–	–	–	–
M25	EXN/M25-050/TC	EXN/M25-075/TC	EXN/M25-100/TC	–	–	–	–	–
M32	EXN/M32-050/TC	EXN/M32-075/TC	EXN/M32-100/TC	EXN/M32-125/TC	–	–	–	–
M40	EXN/M40-050/TC	EXN/M40-075/TC	EXN/M40-100/TC	EXN/M40-125/TC	EXN/M40-150/TC	–	–	–
M50	EXN/M50-050/TC	EXN/M50-075/TC	EXN/M50-100/TC	EXN/M50-125/TC	EXN/M50-150/TC	EXN/M50-200/TC	–	–
M63	EXN/M63-050/TC	EXN/M63-075/TC	EXN/M63-100/TC	EXN/M63-125/TC	EXN/M63-150/TC	EXN/M63-200/TC	–	–
M75	EXN/M75-050/TC	EXN/M75-075/TC	EXN/M75-100/TC	EXN/M75-125/TC	EXN/M75-150/TC	EXN/M75-200/TC	–	–
NPT 1/2	–	EXN/050-075/E	–	–	–	–	–	–
NPT 3/4	EXN/075-050/R	–	EXN/075-100/E	–	–	–	–	–
NPT 1	EXN/100-050/R	EXN/100-075/R	–	EXN/100-125/E	–	–	–	–
NPT 1 1/4	EXN/125-050/R	EXN/125-075/R	EXN/125-100/R	–	EXN/125-150/E	–	–	–
NPT 1 1/2	EXN/150-050/R	EXN/150-075/R	EXN/150-100/R	EXN/150-125/R	–	EXN/150-200/E	–	–
NPT 2	EXN/200-050/R	EXN/200-075/R	EXN/200-100/R	EXN/200-125/R	EXN/200-150/R	–	–	–
NPT 2 1/2	EXN/250-050/R	EXN/250-075/R	EXN/250-100/R	EXN/250-125/R	EXN/250-150/R	EXN/250-200/R	–	EXN/250-300/E
NPT 3	EXN/300-050/R	EXN/300-075/R	EXN/300-100/R	EXN/300-125/R	EXN/300-150/R	EXN/300-200/R	EXN/300-250/R	–

*For Brass version, remove the N to the reference, e.g. EX/M16-050/TC

**For stainless steel 316 version, add S to the reference, e.g. EXS/M16-050/TC

N.B. PG thread convertors available upon request.

CMG House, Station Road, Coleshill, Birmingham, B46 1HT United Kingdom

Tel: +44 (0) 1675 468 213 | Email: sales@kopex.co.uk

www.tnb-hazardous.com

The Company's policy is one of continuous improvement and reserves the right to change specifications at any time without prior notice.

Power and productivity
for a better world™

