

Metric Thread Convertors Enlargers, Reducers and Convertors




Features


- Suitable for use in Zone 1, 2, 21, 22 Exd & Exe
- Available in unplated Brass, Nickel Plated Brass and Stainless Steel 316

Certification & Standards

Approved to:	EN/IEC 60079-0, 60079-1, 60079-7, 60079-31
EC TYPE Examination Certificate:	Baseefa 07ATEX0247X, IECEx BAS 07.0090X
	Ex d IIC Gb
	Ex e IIC Gb
	Ex tb IIIC Db
	Class I Div. 1 ABCD, Class II Div. 1 EFG (does not include M16 & 3/8" NPT or unplated brass products)
	Approved to UL1203
	Approved to CSA C22.2 Nr. 60079-04 and 60079-1

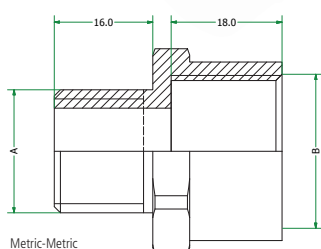

Metric-Metric

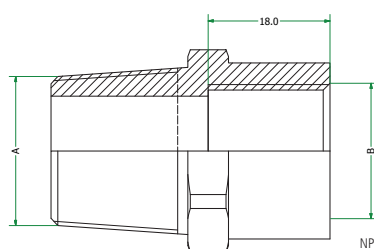

NPT-Metric

Male External Thread (A)	Metric Female Internal Thread (B)							
	M16	M20	M25	M32	M40	M50	M63	M75
M16	–	EXN/M16-M20/E	EXN/M16-M25/E	–	–	–	–	–
M20	EXN/M20-M16/R	–	EXN/M20-M25/E	EXN/M20-M32/E	–	–	–	–
M25	EXN/M25-M16/R	EXN/M25-M20/R	–	EXN/M25-M32/E	EXN/M25-M40/E	–	–	–
M32	EXN/M32-M16/R	EXN/M32-M20/R	EXN/M32-M25/R	–	EXN/M32-M40/E	EXN/M32-M50/E	–	–
M40	EXN/M40-M16/R	EXN/M40-M20/R	EXN/M40-M25/R	EXN/M40-M32/R	–	EXN/M40-M50/E	EXN/M40-M63/E	–
M50	EXN/M50-M16/R	EXN/M50-M20/R	EXN/M50-M25/R	EXN/M50-M32/R	EXN/M50-M40/R	–	EXN/M50-M63/E	EXN/M50-M75/E
M63	EXN/M63-M16/R	EXN/M63-M20/R	EXN/M63-M25/R	EXN/M63-M32/R	EXN/M63-M40/R	EXN/M63-M50/R	–	EXN/M63-M75/E
M75	EXN/M75-M16/R	EXN/M75-M20/R	EXN/M75-M25/R	EXN/M75-M32/R	EXN/M75-M40/R	EXN/M75-M50/R	EXN/M75-M63/R	–
NPT 3/8	EXN/038-M16/TC	–	–	–	–	–	–	–
NPT 1/2	EXN/050-M16/TC	EXN/050-M20/TC	EXN/050-M25/TC	–	–	–	–	–
NPT 3/4	EXN/075-M16/TC	EXN/075-M20/TC	EXN/075-M25/TC	EXN/075-M32/TC	–	–	–	–
NPT 1	EXN/100-M16/TC	EXN/100-M20/TC	EXN/100-M25/TC	EXN/100-M32/TC	EXN/100-M40/TC	–	–	–
NPT 1 1/4	EXN/125-M16/TC	EXN/125-M20/TC	EXN/125-M25/TC	EXN/125-M32/TC	EXN/125-M40/TC	EXN/125-M50/TC	–	–
NPT 1 1/2	EXN/150-M16/TC	EXN/150-M20/TC	EXN/150-M25/TC	EXN/150-M32/TC	EXN/150-M40/TC	EXN/150-M50/TC	EXN/150-M63/TC	–
NPT 2	EXN/200-M16/TC	EXN/200-M20/TC	EXN/200-M25/TC	EXN/200-M32/TC	EXN/200-M40/TC	EXN/200-M50/TC	EXN/200-M63/TC	–
NPT 2 1/2	EXN/250-M16/TC	EXN/250-M20/TC	EXN/250-M25/TC	EXN/250-M32/TC	EXN/250-M40/TC	EXN/250-M50/TC	–	–
NPT 3	EXN/300-M16/TC	EXN/300-M20/TC	EXN/300-M25/TC	EXN/300-M32/TC	EXN/300-M40/TC	EXN/300-M50/TC	–	EXN/300-M75/TC

*For Brass version, remove the N to the reference, e.g. EX/M16-050/TC

**For stainless steel 316 version, add S to the reference, e.g. EXS/M16-050/TC

N.B. PG thread convertors available upon request.

CMG House, Station Road, Coleshill, Birmingham, B46 1HT United Kingdom

Tel: +44 (0) 1675 468 213 | Email: sales@kopex.co.uk

www.tnb-hazardous.com

The Company's policy is one of continuous improvement and reserves the right to change specifications at any time without prior notice.

Power and productivity
for a better world™

