

6

5

4

3

2

1

F

E

D

C

B

A

F

E

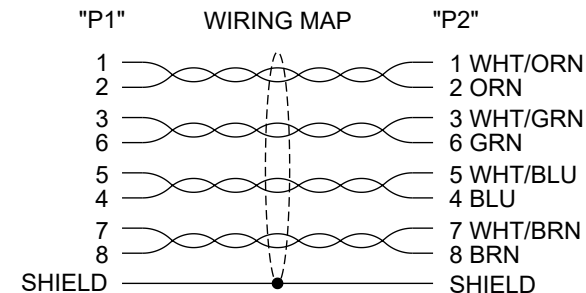
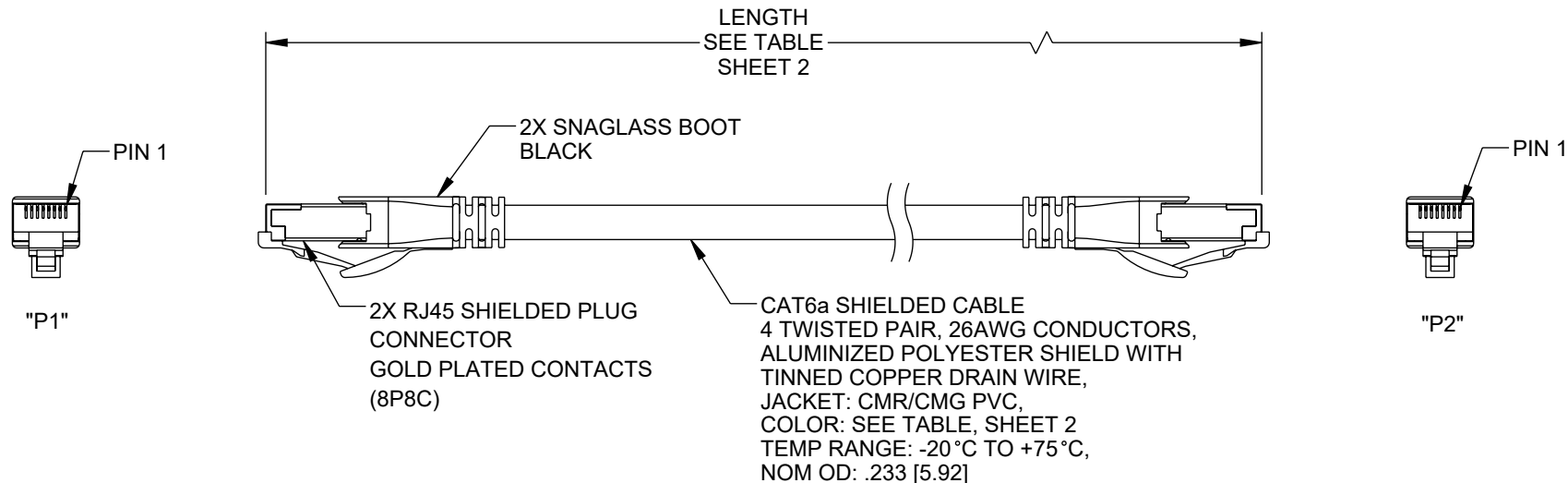
D

C

B

A

REVISION					
ZONE	REV	DESCRIPTION	DATE	CHANGED BY	APPROVED
	A	INITIAL RELEASE	03/28/2024	KGLEBOVA	GUTTADAURO

**NOTES:**

1. LENGTHS OVER 10 METERS (32.8 FT) ARE CHANNEL RATED.
2. CABLE ASSEMBLY SHALL BE TESTED FOR CONTINUITY.
3. CABLE ASSEMBLY SHALL BE INDIVIDUALLY PACKAGED IAW L-COM SPECIFICATION PS-0031.

REGULATORY COMPLIANCE:

EU RoHS DIRECTIVE (MOST RECENT RELEASED VERSION).

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF INFINITE ELECTRONICS, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF INFINITE ELECTRONICS, INC. IS PROHIBITED. THESE COMMODITIES, TECHNOLOGY OR SOFTWARE WERE EXPORTED FROM THE UNITED STATES IN ACCORDANCE WITH THE EXPORT ADMINISTRATION REGULATIONS. DIVERSION CONTRARY TO U.S. LAW PROHIBITED.

6

5

4

3

2

1

UNLESS OTHERWISE SPECIFIED
LEADING DIMENSIONS ARE INCHES
DIMENSIONS IN [] ARE MILLIMETERS

 
TOLERANCES:	
X = ±.2 [5]	FRACTIONS ± 1/32
.XX = ±.02 [0.5]	ANGLES ± 1°
.XXX = ±.005 [0.13]	

CABLE LENGTH TOLERANCES:	
≤12 [305]	±.1 [25] / -0
>12 [305] ≤ 60 [1524]	±.2 [51] / -0
>60 [1524] ≤ 120 [3048]	±.4 [102] / -0
>120 [3048] ≤ 300 [7620]	±.6 [152] / -0
>300 [7620]	±.5% / -0

ALL DIMENSIONS ARE FOR REFERENCE ONLY
AND SUBJECT TO CHANGE WITHOUT NOTICE.
UN-DIMENSIONED/NON-CRITICAL FEATURES
MAY VARY IN SIZE AND LOCATION
COLORS MAY VARY

L-com
an INFINIT® brand

Website: www.L-com.com
Phone: 1.800.341.5266 | 1.978.682.6936



INTERPRET ALL DIMENSIONS AND
TOLERANCES PER ASME Y14.5

SCALE	SHEET
NONE	1 OF 2

DESCRIPTION				
Cat6a FUTP RJ45 CMR CMG 26AWG				
SIZE	CAGE CODE	DRAWN BY	ITEM NO.	REV
A	43321	KGLEBOVA	TRD626ASR	A

6

5

4

3

2

1

F

F

E

E

D

D

C

C

B

B

A

A

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-BLK-1F	BLACK	1.0	0.30
TRD626ASR-BLK-2F	BLACK	2.0	0.61
TRD626ASR-BLK-3F	BLACK	3.0	0.91
TRD626ASR-BLK-5F	BLACK	5.0	1.52
TRD626ASR-BLK-7F	BLACK	7.0	2.13
TRD626ASR-BLK-10F	BLACK	10.0	3.05
TRD626ASR-BLK-15F	BLACK	15.0	4.57
TRD626ASR-BLK-25F	BLACK	25.0	6.10
TRD626ASR-BLK-50F	BLACK	50.0	7.62
TRD626ASR-BLK-75F	BLACK	75.0	9.14
TRD626ASR-BLK-100F	BLACK	100.0	30.48

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-BLU-1F	BLUE	1.0	0.30
TRD626ASR-BLU-2F	BLUE	2.0	0.61
TRD626ASR-BLU-3F	BLUE	3.0	0.91
TRD626ASR-BLU-5F	BLUE	5.0	1.52
TRD626ASR-BLU-7F	BLUE	7.0	2.13
TRD626ASR-BLU-10F	BLUE	10.0	3.05
TRD626ASR-BLU-15F	BLUE	15.0	4.57
TRD626ASR-BLU-25F	BLUE	25.0	6.10
TRD626ASR-BLU-50F	BLUE	50.0	7.62
TRD626ASR-BLU-75F	BLUE	75.0	9.14
TRD626ASR-BLU-100F	BLUE	100.0	30.48

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-GRY-1F	GRAY	1.0	0.30
TRD626ASR-GRY-2F	GRAY	2.0	0.61
TRD626ASR-GRY-3F	GRAY	3.0	0.91
TRD626ASR-GRY-5F	GRAY	5.0	1.52
TRD626ASR-GRY-7F	GRAY	7.0	2.13
TRD626ASR-GRY-10F	GRAY	10.0	3.05
TRD626ASR-GRY-15F	GRAY	15.0	4.57
TRD626ASR-GRY-25F	GRAY	25.0	6.10
TRD626ASR-GRY-50F	GRAY	50.0	7.62
TRD626ASR-GRY-75F	GRAY	75.0	9.14
TRD626ASR-GRY-100F	GRAY	100.0	30.48

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-RED-1F	RED	1.0	0.30
TRD626ASR-RED-2F	RED	2.0	0.61
TRD626ASR-RED-3F	RED	3.0	0.91
TRD626ASR-RED-5F	RED	5.0	1.52
TRD626ASR-RED-7F	RED	7.0	2.13
TRD626ASR-RED-10F	RED	10.0	3.05
TRD626ASR-RED-15F	RED	15.0	4.57
TRD626ASR-RED-25F	RED	25.0	6.10
TRD626ASR-RED-50F	RED	50.0	7.62
TRD626ASR-RED-75F	RED	75.0	9.14
TRD626ASR-RED-100F	RED	100.0	30.48

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-VLT-1F	VIOLET	1.0	0.30
TRD626ASR-VLT-2F	VIOLET	2.0	0.61
TRD626ASR-VLT-3F	VIOLET	3.0	0.91
TRD626ASR-VLT-5F	VIOLET	5.0	1.52
TRD626ASR-VLT-7F	VIOLET	7.0	2.13
TRD626ASR-VLT-10F	VIOLET	10.0	3.05
TRD626ASR-VLT-15F	VIOLET	15.0	4.57
TRD626ASR-VLT-25F	VIOLET	25.0	6.10
TRD626ASR-VLT-50F	VIOLET	50.0	7.62
TRD626ASR-VLT-75F	VIOLET	75.0	9.14
TRD626ASR-VLT-100F	VIOLET	100.0	30.48

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-WHT-1F	WHITE	1.0	0.30
TRD626ASR-WHT-2F	WHITE	2.0	0.61
TRD626ASR-WHT-3F	WHITE	3.0	0.91
TRD626ASR-WHT-5F	WHITE	5.0	1.52
TRD626ASR-WHT-7F	WHITE	7.0	2.13
TRD626ASR-WHT-10F	WHITE	10.0	3.05
TRD626ASR-WHT-15F	WHITE	15.0	4.57
TRD626ASR-WHT-25F	WHITE	25.0	6.10
TRD626ASR-WHT-50F	WHITE	50.0	7.62
TRD626ASR-WHT-75F	WHITE	75.0	9.14
TRD626ASR-WHT-100F	WHITE	100.0	30.48

ITEM NO.	COLOR	LENGTH	
		FEET	METERS
TRD626ASR-YLW-1F	YELLOW	1.0	0.30
TRD626ASR-YLW-2F	YELLOW	2.0	0.61
TRD626ASR-YLW-3F	YELLOW	3.0	0.91
TRD626ASR-YLW-5F	YELLOW	5.0	1.52
TRD626ASR-YLW-7F	YELLOW	7.0	2.13
TRD626ASR-YLW-10F	YELLOW	10.0	3.05
TRD626ASR-YLW-15F	YELLOW	15.0	4.57
TRD626ASR-YLW-25F	YELLOW	25.0	6.10
TRD626ASR-YLW-50F	YELLOW	50.0	7.62
TRD626ASR-YLW-75F	YELLOW	75.0	9.14
TRD626ASR-YLW-100F	YELLOW	100.0	30.48

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF INFINITE ELECTRONICS, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF INFINITE ELECTRONICS, INC. IS PROHIBITED. THESE COMMODITIES, TECHNOLOGY OR SOFTWARE WERE EXPORTED FROM THE UNITED STATES IN ACCORDANCE WITH THE EXPORT ADMINISTRATION REGULATIONS. DIVERSION CONTRARY TO U.S. LAW PROHIBITED.

ALL DIMENSIONS ARE FOR REFERENCE ONLY AND SUBJECT TO CHANGE WITHOUT NOTICE. UN-DIMENSIONED/NON-CRITICAL FEATURES MAY VARY IN SIZE AND LOCATION. COLORS MAY VARY.

 an INFINIT® brand Website: www.L-com.com Phone: 1.800.341.5266 1.978.682.6936		 INTERPRET ALL DIMENSIONS AND TOLERANCES PER ASME Y14.5	
		SCALE NONE	SHEET 2 OF 2
DESCRIPTION Cat6a FUTP RJ45 CMR CMG 26AWG			
SIZE A	CAGE CODE 43321	DRAWN BY KGLEBOVA	ITEM NO. TRD626ASR
			REV A