

## SMA Male to 10-32 Male Cable RG-316 Coax in 48 Inch

### Electrical Specifications

| Description             | Min | Typ         | Max    | Units        |
|-------------------------|-----|-------------|--------|--------------|
| Frequency Range         | DC  |             | 1,000  | MHz          |
| VSWR                    |     |             | 1.35:1 |              |
| Velocity of Propagation |     | 70          |        | %            |
| Capacitance             |     | 32 [104.99] |        | pF/ft [pF/m] |

### Mechanical Specifications

#### Cable Assembly

|          |                   |
|----------|-------------------|
| Length   | 48 in [121.92 cm] |
| Diameter | 0.315 in [8 mm]   |

#### Cable

|                                      |                            |
|--------------------------------------|----------------------------|
| Cable Type                           | RG-316                     |
| Impedance                            | 50 Ohms                    |
| Inner Conductor Type                 | Solid                      |
| Inner Conductor Material and Plating | Copper, Silver             |
| Dielectric Type                      | PTFE                       |
| Number of Shields                    | 1                          |
| Shield Layer 1                       | Silver Plated Copper Braid |
| Jacket Material                      | FEP, Tan                   |
| Jacket Diameter                      | 0.098 in [2.49 mm]         |

### Connectors

| Description                | Connector 1        | Connector 2   |
|----------------------------|--------------------|---------------|
| Type                       | SMA Male           | 10-32 Male    |
| Impedance                  | 50 Ohms            | 50 Ohms       |
| Contact Material & Plating | Brass, Gold        | Brass, Gold   |
| Contact Plating Spec.      | 50μ in. minimum    | MIL-G-45204   |
| Dielectric Type            | PTFE               | PTFE          |
| Hex Size                   | 5/16 inch          |               |
| Torque                     | 4 in-lbs [0.45 Nm] |               |
| Body Material & Plating    | Brass, Nickel      | Brass, Nickel |
| Body Plating Spec.         | 100μ in. minimum   |               |

### Environmental Specifications

#### Temperature

|                 |                   |
|-----------------|-------------------|
| Operating Range | -65 to +165 deg C |
|-----------------|-------------------|

**Compliance Certifications** (visit [www.FairviewMicrowave.com](http://www.FairviewMicrowave.com) for current document)

### Plotted and Other Data

Notes:




### Configuration:

- SMA Male
- 10-32 Male
- RG-316

Fairview Microwave  
1130 Junction Dr. #100  
Allen, TX 75013  
Tel: 1-800-715-4396 / (972) 649-6678  
Fax: (972) 649-6689  
[www.fairviewmicrowave.com](http://www.fairviewmicrowave.com)  
[sales@fairviewmicrowave.com](mailto:sales@fairviewmicrowave.com)

### Typical Performance Data

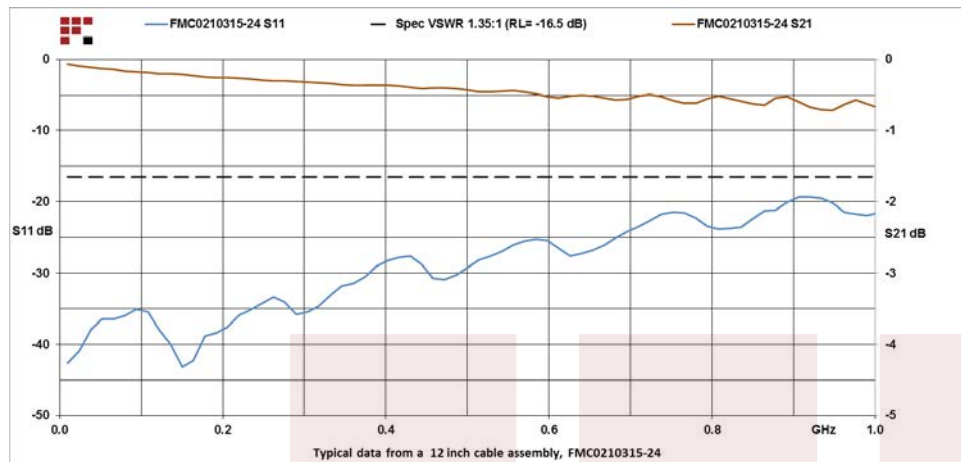

### How to Order

Part Number Configuration:

**FMC0210315 - xx uu**

cm = Centimeters  
<blank> = Inches  
Length


Example: FMC0210315-12 = 12 inches long cable  
FMC0210315-100cm = 100 cm long cable

SMA Male to 10-32 Male Cable RG-316 Coax in 48 Inch from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [SMA Male to 10-32 Male Cable RG-316 Coax in 48 Inch FMC0210315-48](http://www.fairviewmicrowave.com/sma-male-10-32-male-cable-rg316-coax-fmc0210315-48-p.aspx)

URL: <http://www.fairviewmicrowave.com/sma-male-10-32-male-cable-rg316-coax-fmc0210315-48-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

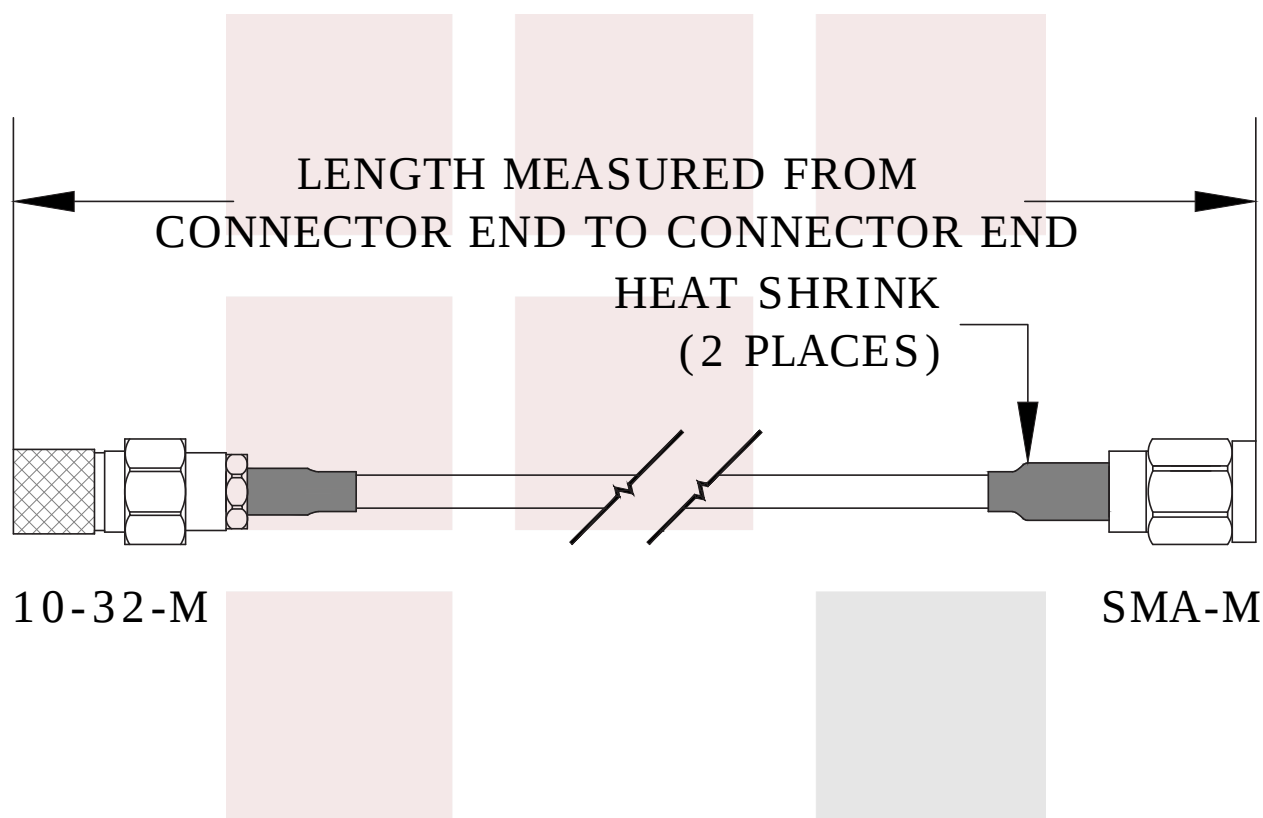

**FAIRVIEW MICROWAVE INC.**  
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

NOTES:  
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.  
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.  
3. DIMENSIONS ARE IN INCHES [mm].

TITLE  
SMA Male to 10-32 Male Cable RG-316 Coax in 48  
Inch

|          |        |            |  |           |     |       |        |
|----------|--------|------------|--|-----------|-----|-------|--------|
| DWG NO   |        | FMC0210315 |  | CAGE CODE |     | 3FKR5 |        |
| CAD FILE | 101514 | SHEET      |  | SCALE     | N/A | SIZE  | A 5568 |