


4 Port PCI Express Low Profile High Speed USB Card - TAA

Product ID: PEXUSB4DP

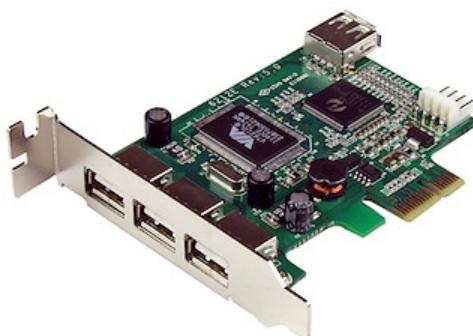

The PEXUSB4DP is a low profile 4 port USB card designed for versatility and performance.

Providing simple system expansion for added peripheral connections, this PCI Express USB card adds 3 external USB 2.0 slots and 1 internal USB 2.0 slot, with support for high speed USB 2.0 data transfer rates of up to 480 Mbps, and includes WHQL certified drivers and easy plug and play installation.

Capable of adapting to virtually any PC case form factor, the low profile USB card includes a standard profile bracket for installation in full form factor cases.

Certifications, Reports and Compatibility



Applications

- Add USB 2.0 connectivity to any PCIe based desktop, workstation or server

- Expand on a computer's USB 2.0 capabilities with 4 additional ports for more USB device connections
- Add an internal USB port to connect internal or front-bay mounted USB devices
- Connect additional external hard drives, CD/DVD drives, MP3 players, printers, scanners, webcams, game controllers, digital cameras, etc. to a computer system

Features

- 3 external and 1 internal USB 2.0 port
- High Speed USB 2.0 compliant, with transfer rates up to 480Mbps
- Backward compatible with USB 1.0/1.1 devices
- Provide up to 500mA of power per port with dedicated power input
- Plug-and-Play compatible
- Includes a full profile installation bracket

Hardware

Warranty	2 Years
Ports	4
Interface	USB 2.0
Bus Type	PCI Express
Card Type	Low Profile (SP bracket incl.)
Industry Standards	PCI Express One Lane 2.5Gb/s
Chipset ID	VIA/VLI - VT6212
	ASMedia ASM1083

Performance

Type and Rate	USB 2.0 - 480 Mbit/s
---------------	----------------------

Connector(s)

Connector Type(s)	1 - PCI Express x1
Internal Ports	1 - SP4 (4 pin, Small Drive Power)
	1 - USB 2.0 Type-A (4 pin, 480Mbps)

External Ports	3 - USB 2.0 Type-A (4 pin, 480Mbps)
----------------	-------------------------------------

Software

OS Compatibility	Windows 2000, XP, Vista, 7, 8, 8.1, 10, 11
	Windows Server 2003, 2008 R2, 2012, 2016, 2019, 2022
	Mac OS X 10.6 to 10.10
	Linux 3.5.x and up - LTS Versions only

Special Notes / Requirements

System and Cable Requirements	PCI Express enabled computer with an available PCI Express x1 slot or higher
-------------------------------	------------------------------------------------------------------------------

Environmental

Operating Temperature	-0C to 75C (32F to 167F)
Storage Temperature	-40C to 125C (-40F to 257F)
Humidity	80% RH

Physical Characteristics

Color	Green
Material	Steel
Product Length	3.5 in [9.0 cm]
Product Width	3.1 in [8.0 cm]
Product Height	0.8 in [2.0 cm]
Weight of Product	1.6 oz [46.0 g]

Packaging Information

Package Quantity	1
Package Length	6.7 in [17.0 cm]
Package Width	5.7 in [14.4 cm]
Package Height	1.3 in [3.2 cm]
Shipping (Package) Weight	4.2 oz [120.0 g]

What's in the Box

Included in Package	1 - PCI Express USB 2.0 Card
	1 - Full Profile Bracket
	1 - Driver CD
	1 - Instruction Manual

**Warranty
Information**

Warranty	2 Years
----------	---------

****Product appearance and specifications are subject to change without notice.***

