


6ft Micro USB Cable - A to Micro B

Product ID: UUSBHAUB6

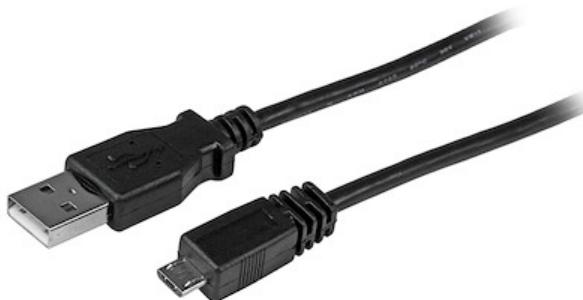

The UUSBHAUB6 6-foot USB A to Micro USB cable features one USB 'A' male connector, and one 'Micro-B' male connector, providing a high quality connection to USB 2.0 mobile devices (such as BlackBerry or Android-based cellular phones, digital cameras, Tablet PC devices and GPS systems) that use a Micro USB connector to a USB capable computer for everyday tasks such as data synchronization and file transfers.

This high quality cable is backed by StarTech.com's Lifetime Warranty to ensure dependable, long-lasting connections between Micro USB and USB devices.

Certifications, Reports and Compatibility



Applications

- An ideal replacement cable for connecting mobile devices to a USB capable computer

Features

- Supports high speed data transfer rates up to 480 Mbps
- Aluminum-Mylar Foil with Braided Shielding
- High quality USB 'A' and USB 'Micro-B'connectors
- Durable PVC construction

Hardware

Warranty	Lifetime
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Shield Material	Aluminum-Mylar Foil with Braid

Performance

Type and Rate	USB 2.0 - 480 Mbit/s
---------------	----------------------

Connector(s)

Connector A	1 - USB 2.0 Type-A (4 pin, 480Mbps)
Connector B	1 - USB Micro-B (5 pin)

Environmental

Operating Temperature	-20C to 60C (-4F to 140F)
Storage Temperature	-10C to 30C (14F to 86F)
Humidity	30%-75% RH

Physical Characteristics

Color	Black
Wire Gauge	28 AWG
Cable Length	6.0 ft [1.8 m]
Product Length	6.0 ft [1.8 m]
Product Width	0.6 in [1.6 cm]
Product Height	0.3 in [0.7 cm]
Weight of Product	1.6 oz [46.0 g]

Packaging Information

Package Quantity	1
Package Length	5.3 in [13.5 cm]

Package Width 5.0 in [12.6 cm]

Package Height 0.6 in [1.6 cm]

Shipping (Package)
Weight 1.7 oz [48.0 g]

What's in the Box

Included in Package 1 - 6ft Micro USB Cable - A to Micro B

**Warranty
Information**

Warranty Lifetime

**Product appearance and specifications are subject to change without notice.*

