


1U Hinged Wall Mount Patch Panel Bracket - 6 inch Deep - 19" Patch Panel Swing Rack for Shallow Network Equipment- 17lbs

Product ID: WALLMOUNTH1

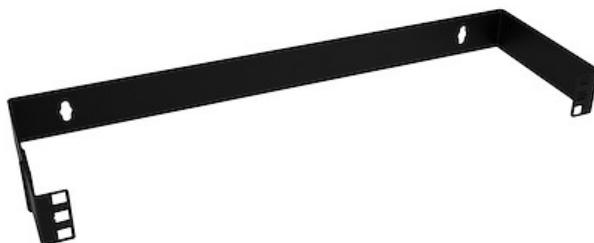

The WALLMOUNTH1 1U 19in Hinged Wall Mounting Bracket for Patch Panels is 6in deep and sturdily designed to provide a dependable solution for mounting a patch panel, or other slim 19in networking equipment to a wall.

The patch panel wall mount features a hinged design for easy access to configuration buttons, ports and cables. The wall mounting holes are spaced 16 in. apart, making it suitable for mounting on almost any wall, based on common wall-frame stud spacing.

Certifications, Reports and Compatibility



Applications

- Wall mount patch panels and other slim 19" rackmount equipment

Features

- **STURDY CONSTRUCTION:** The 1U 19in hinged wall mounting bracket for patch panels is 6in deep and sturdily designed to mount a patch panel, or other slim 19in networking, data, IT equipment to a wall
- **OPTIMIZED WORKSPACE:** This durable 1U 19in hinged wall mounting bracket has a maximum mounting depth of 5.8in [14.8cm] and a maximum weight capacity of 17.7lb [8kg]

- **EASY CABLE MANAGEMENT:** The patch panel swing bracket features a hinged design for easy access to configuration buttons, ports and cables, and to the rear of the equipment for easy adjustment
- **STANDARDIZED HOLE SIZING:** The mounting holes on the 1U network rack are 16in apart, exactly matching standard drywall construction framework to ensure simple and secure wall-stud anchoring
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this wall mounting bracket is backed for 2-years, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Warranty	2 Years
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Open Frame
U Height	1U
Mounting Rail Profile	L-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

Performance

Weight Capacity	17.6 lb [8 kg]
-----------------	----------------

Physical Characteristics

Color	Black
Construction Material	Steel

Product Measurements

Product Length	6.0 in [15.2 cm]
Product Width	19.7 in [50.1 cm]
Product Height	1.7 in [4.4 cm]
Weight of Product	1.9 lb [0.8 kg]
Maximum Mounting Depth	5.8 in [14.8 cm]

Packaging

Information

Flat Pack (Assembly Required)	No
Package Length	8.1 in [20.7 cm]
Package Width	20.9 in [53.0 cm]
Package Height	3.1 in [7.9 cm]
Shipping (Package) Weight	2.8 lb [1.3 kg]

What's in the Box

Included in Package	1 - Wall-Mount Rack
	4 - M6 Screws
	4 - M6 Cage Nuts
	4 - Plastic Washers
	2 - Wall Screws
	2 - Plastic Anchors

Warranty Information

Warranty	2 Years
----------	---------

**Product appearance and specifications are subject to change without notice.*

