



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	2
Wire Size/AWG	24 - 20
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 16.60 mm
Size	3B
Suggested matching part	FGG.3B.846.CLCD81Z
Series	B - Indoor keyed

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/eeg-3b-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	2
Contact Termination Coax	Crimp
R (max)	5.8 mOhm
Insert configuration value	3B.846 - 2 Coax (50 Ohm), 6 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 A
OHM	50
Test voltage (kV DC)	1.3
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.34 mm ² (AWG 22)
Cable type	RG 174 A/U, RG 188 A/U, RG 316 /U
Contact Dia.	0.7 mm (0.03in)
Wire Size/AWG	24 - 20
Gender	Standard

Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	32.31 g

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/eeg-3b-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	2.00 - 16.60 mm
------------------------------------	-----------------

Drawings

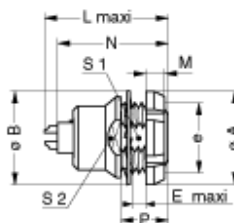

Dimensions

	S1	S2	E	P	L	M	N	e	A	B
mm.	16.5	20	6.1	12	30.7	4.5	28.1	M18x1.0	24	25
in.	0.65	0.79	0.24	0.47	1.21	0.18	1.11		0.94	0.98

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/eeg-3b-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories	
Replacement contact	EGG.3B.660.ZZM
Compatible cap	BRE.3S.200.NAS
Tools	
Die Tool	DPE.99.103.8K
Positionner	DCE.91.093.BVM
Extraction tool	DCC.09.05B.LAG
Crimp tool	DPC.91.701.V
Spanner wrench	Socket for torque wrench DCM.65.200.AZ