



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	10
Nb of contacts Coax	1
Wire Size/AWG	30 - 22
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	6.70 - 7.50 mm
Size	3P
Series	REDEL P - Push-Pull

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/fgg-3p-809-xlwd75b.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	10
Contact Termination Low voltage	Solder
Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Crimp
R (max)	5.8 mOhm
Insert configuration value	3P.809 - 1 Coax (50 Ohm) + 9 Low Voltage + 1 Ground contact
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	4 A
Impedance	50 Ohms
Test voltage contact-contact	1.6 kV DC
Air clearance	0.9 mm
Creepage distance	0.9 mm
Contact Dia.	0.7 mm (0.03in)
Wire Size/AWG	30 - 22

Form & Material

Shell style / Model id	FG - Straight plug with key and cable seal
Plug	Straight
Housing material	PSU (Polysulfone), white
Locking system	Push-pull
Keying	User configurable, 1 of 11 key positions. Plug: male contacts, Receptacle: female contacts
Colour	White
Variant	White front ring
Weight	22.14 g

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/fgg-3p-809-xlwd75b.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Energy and Industrial, Medical, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP61
Endurance	>3000 mating cycles
Temperature range	-50°C / +150°C
F ret (max)	200 N
F ret (min)	100 N
Steam sterilization	Fully sterilizable (Steam, Gamma, ETO) following our protocols and tests in line with ISO 11134 and IEC 60601-1 standards. For more details on sterilization methods and cycles, please contact us.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	6.70 - 7.50 mm

Drawings

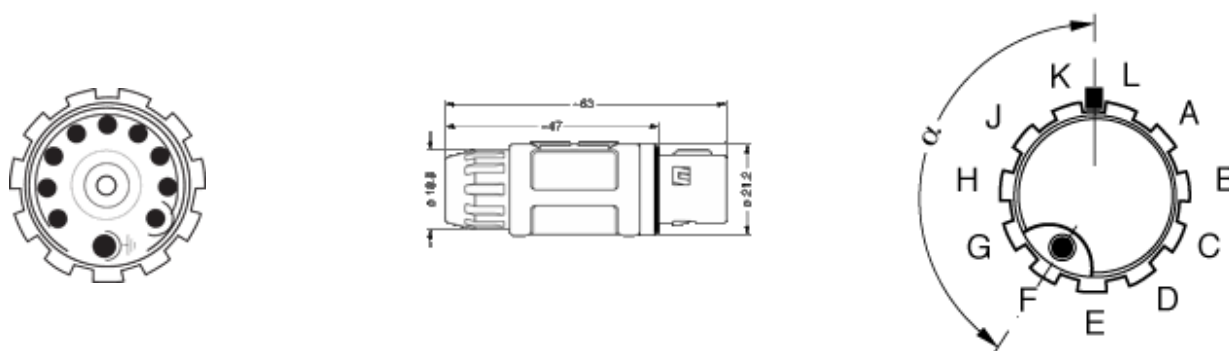

Dimensions

	A	L
mm.	21.2	63
in.	0.83	2.48

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/fgg-3p-809-xlwd75b.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Replacement contact

[EGG.3P.661.ZZY](#)

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/fgg-3p-809-xlwd75b.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.