




Application Tooling > Hand Crimping Tools

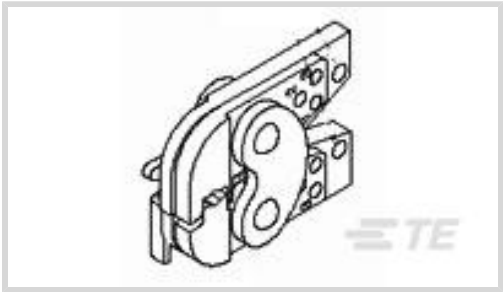

Tool Grade: **Premium Crimp Tooling**
Ratchet Configuration: **Not Releasable, Not Adjustable**
Die Sets Type: **Fixed In Tool**
Specification Type: **TE Product Specification (114-)**
Power Technology Type: **Battery (110v), Battery (220v)**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	TE Product Specification (114-)
Power Technology Type	Battery (110v), Battery (220v)
Tooling Type	Double Action Hand Tool, Head Assembly

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free





Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

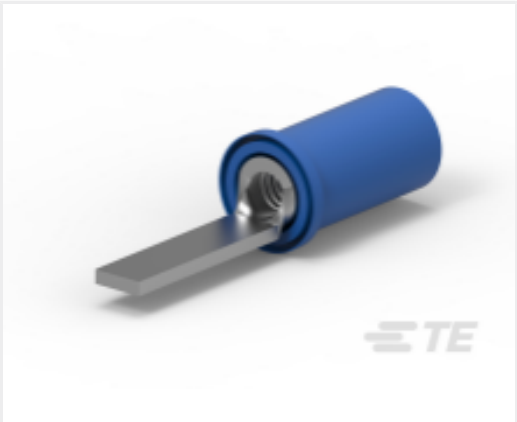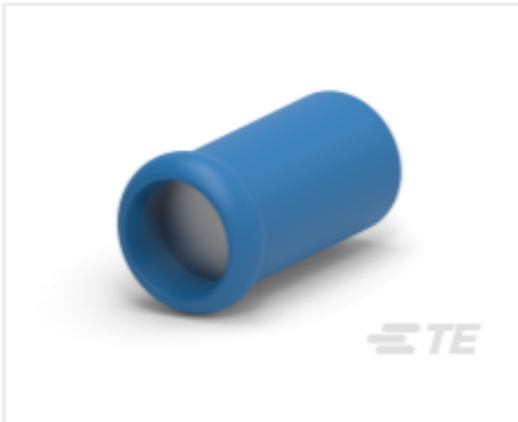
 TE Part # 327748 TAB, PIDG 16-14	 TE Part # CAT-P592-R472A PIDG Ring Tongue Terminals	 TE Part # 326741 TERMINAL, PG SPD 16-14 8	 TE Part # 324227 PG SHUR PLUG 16-14
 TE Part # 735159 250 PIDG FF	 TE Part # CAT-P592-R2456 PIDG Rectangular Tongue Terminals	 TE Part # CAT-P592-F614 PIDG Flanged Spade Tongue Terminals	 TE Part # 328527 TERMINAL, PG R 16-14 8
 TE Part # CAT-P592-SP118 PIDG Spade Tongue Terminals	 TE Part # 328308 SPARE WIRE CAP, BLU, 16-14 AWG	 TE Part # 324228 PG SHUR PLUG 16-14	 TE Part # 324165 TERMINAL, PG SPD FLG 16-14 6





TE Part # 322994

TERMINAL,PG SPD 16-14 6

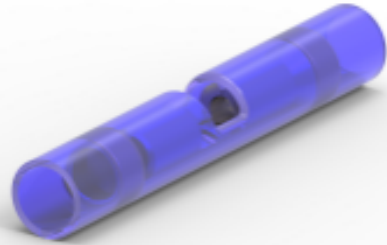

TE Part # 327583

SPLICE BUTT PIDG 16-14/22-18

Also in the Series | B&H BET



Hand Crimping Tools(2)



Mechanical Connectors(5)

Also in the Series | PIDG



Compression Connectors(50)



Crimp Wire Pins, Tabs & Ferrules(41)




Hand Crimping Tools(2)



Knife Disconnects(11)



Ring Terminals(589)

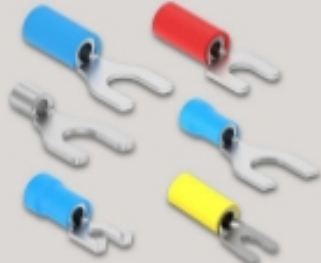

Spade Terminals(228)



Special Purpose Terminals(1)



Splices(41)

Customers Also Bought



TE Part #CAT-D48-ST273
DEUTSCH Solid Contacts



TE Part #CAT-D487-W416
Wedgelocks: DEUTSCH DT




TE Part #DT04-2P
REC, 2P, GRY, N



TE Part #DT06-2S
PLG, 2P, GRY, N



TE Part #206070-8
CABLE CLAMP KIT #17

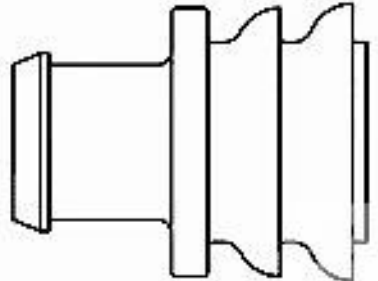

TE Part #281934-2
SINGLE WIRE SEAL



TE Part #CAT-AM71-CH8172
AMP SUPERSEAL 1.5MM,
CONNECTOR HOUSING

Documents

Datasheets & Catalog Pages

ENG_CS_1-1773859-6_0915

English

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (U.S.)

English