




Application Tooling > Heat Shrink Equipment

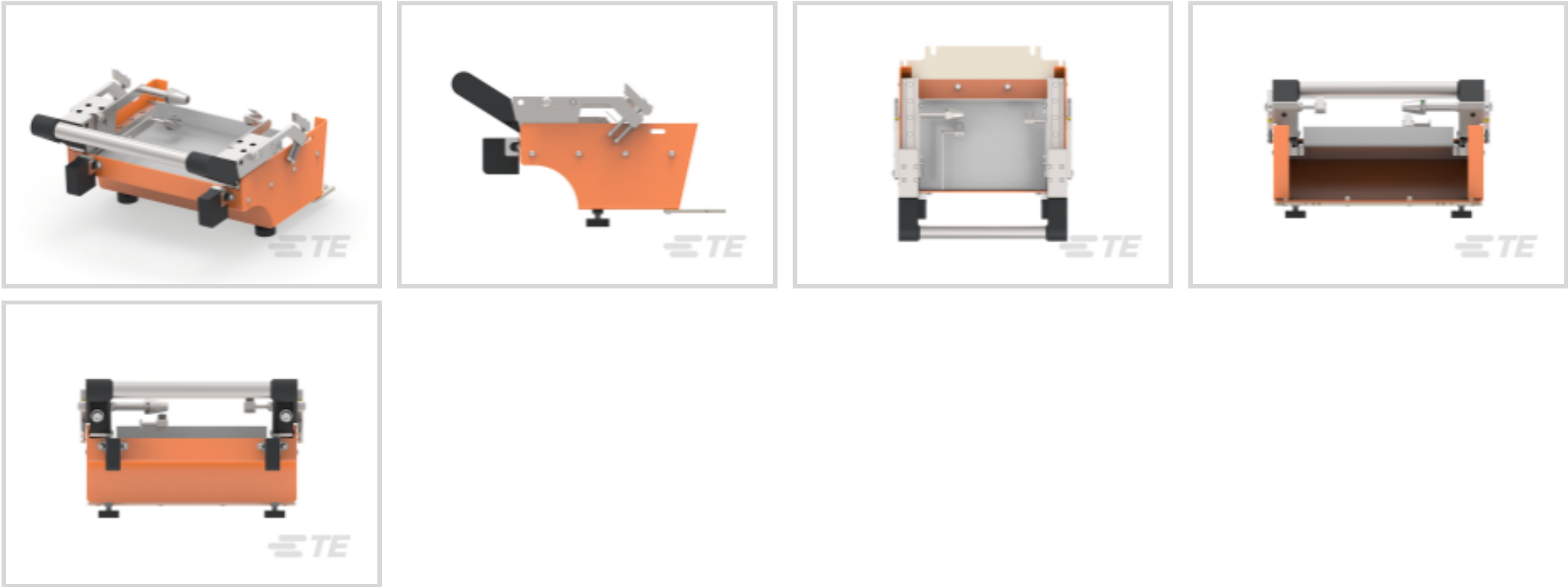

Equipment Processing Type: **Discrete**

Applicable Region: **Worldwide**

Heat Shrink Equipment Application: **In-Line Splice, Stub Splice**

Tooling Type: **Heating Tool**

Spare Parts Tooling Type: **RBK Processor**

Features

Product Type Features

Spare Parts Tooling Type	RBK Processor
--------------------------	---------------

Dimensions

Tubing Outer Diameter (Max)	≤ 19 mm[≤ .75 in]
Tubing Length (Max)	≤ 65 mm[≤ 2.56 in]

Product Availability

 
Applicable Region	Worldwide
-------------------	-----------

Other

Equipment Processing Type	Discrete
Heat Shrink Equipment Application	In-Line Splice, Stub Splice
Tooling Type	Heating Tool
Substrate Outside Diameter Max	9.5 mm

Compatible Parts



TE Part # 6-2234788-8 CABLE CLAMPER, FLATTEN	TE Part # 7-2234788-0 STANDARD TOOL KIT	TE Part # 4-2234788-9 END CAP HOLDER	TE Part # 4-2234788-7 CABLE FLATNESS KEEPER, RIGHT
 TE Part # 7-2234788-1 CABLE CLAMPER, LEFT	 TE Part # 1-2234800-3 RBK-X1, W/ AIR COOLING	 TE Part # 2384437-1 KIT, TERMINAL HOLDER, RBK	TE Part # 4-2234788-8 CABLE FLATNESS KEEPER, LEFT
TE Part # 7-2234788-2 CABLE CLAMPER, RIGHT	TE Part # 8-529533-2 DOUBLE FIXTURE ID 4.5MM	 TE Part # 1-2234800-1 RBK-X1, AUTO TRIGGER	TE Part # 7-2234788-4 END CAP HOLDER, DUAL
TE Part # 6-529533-1 FIXTURE ID 4.5MM CPL.	TE Part # 7-2234788-3 KIT, TERMINAL HOLDER, RBK	TE Part # 7-2234788-5 CABLE CLAMPER, CIRCLE	 TE Part # 2234800-1 RBK-X1 STD
TE Part # 2-2234788-9 HOLDER KIT, STUB TOOL	TE Part # 8-529533-3 DOUBLE FIXTURE ID 5.5MM	TE Part # 8-529533-4 DOUBLE FIXTURE ID 8MM	TE Part # 6-529533-2 FIXTURE ID 5.5MM CPL.

Documents

Product Drawings
RBK FIXTURE, CAP W/ FLATTEN BRKT



English

Instruction Sheets

Instruction Sheet (non U.S.)

English

Instruction Sheet (non U.S.)

French

Instruction Sheet (non U.S.)

Instruction Sheet (non U.S.)

Instruction Sheet (non U.S.)

Instruction Sheet (non U.S.)

Instruction Sheet (non U.S.)

Instruction Sheet (non U.S.)

German