




LUMAWISE | LUMAWISE Dimming Receptacle

TE Internal #: 2376865-3
Connector, Not Rotatable, Wire-to-Component, 5 Position,
Sealable, Power & Signal, LUMAWISE Dimming Receptacle, ANSI
Street Lighting Receptacles
[View on TE.com >](#)

Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Receptacles >
LUMAWISE Endurance N Poke-In: Streetlight Dimming Receptacles

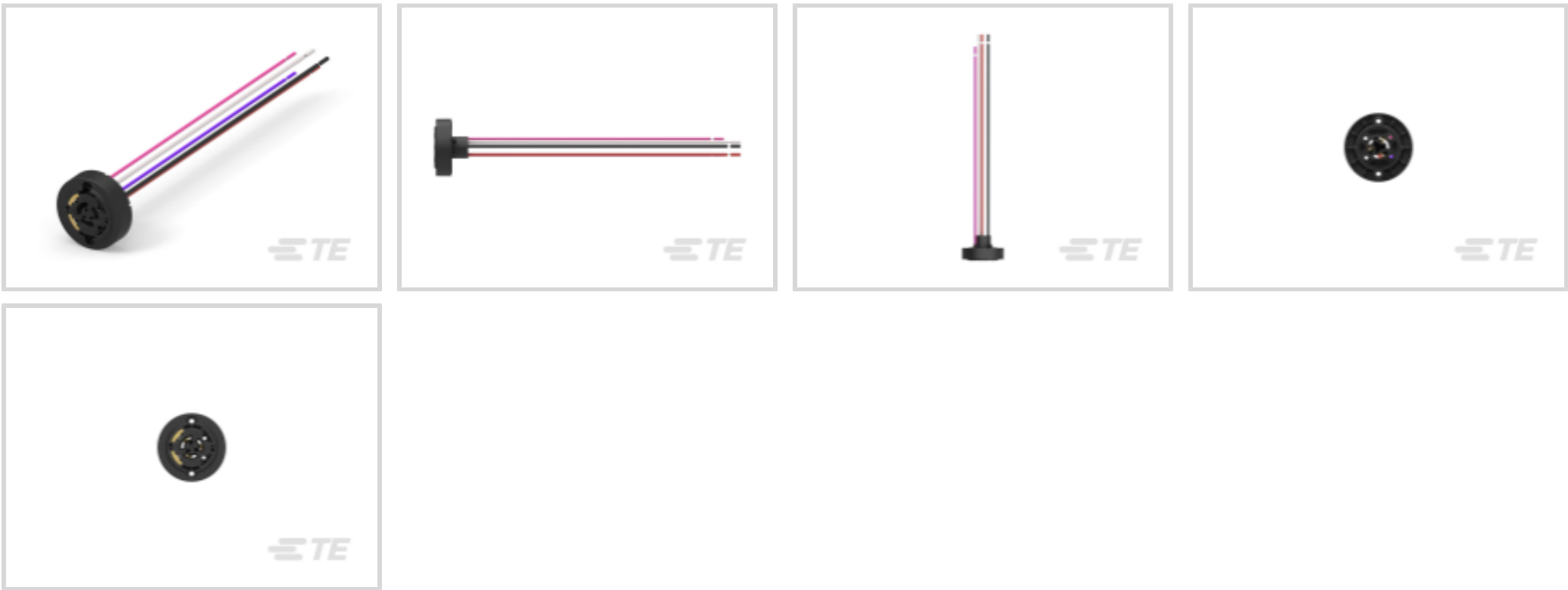

Lighting Product Type: **Connector**
Lighting Connector Features Included: **Not Rotatable**
Connector System: **Wire-to-Component**
Number of Positions: **5**
Sealable: **Yes**

[All LUMAWISE Endurance N Poke-In: Streetlight Dimming Receptacles \(33\)](#)

Features

Product Type Features

Connector & Contact Terminates To	Wire & Cable
Lighting Product Type	Connector
Connector System	Wire-to-Component
Sealable	Yes

Configuration Features

Lighting Connector Features Included	Not Rotatable
Number of Positions	5

Electrical Characteristics

Operating Voltage	600 VDC
-------------------	---------

Body Features

Primary Product Color	Black
-----------------------	-------



Contact Features

Contact Current Rating (Max)	15 A
Contact Mating Area Plating Material	Gold (Au)

Dimensions

Wire Size	18 – 14 AWG
-----------	-------------

Usage Conditions

Operating Temperature Range	-40 – 85 °C[-40 – 185 °F]
-----------------------------	---------------------------

Operation/Application

Circuit Application	Power & Signal
---------------------	----------------

Industry Standards

Compatible With Agency/Standards Products	ANSI
---	------

Compatible Parts



TE Part # 1-2336396-2
ASSEMBLY, LIGHT CONTROLLER
BASE, W/VENT



TE Part # 1-2213871-1
LIGHT CONTROLLER BASE ASSY,
76MM DIA,5POS



TE Part # 2382635-1
LUMAWISE POWER INPUT TERMINAL
BLOCK (TB)




TE Part # 1-2213871-2
LIGHT CONTROLLER BASE ASSY,
81MM DIA,5POS



TE Part # 1-2336396-1
ASSEMBLY, LIGHT CONTROLLER
BASE, W/VENT

Also in the Series | LUMAWISE Dimming Receptacle

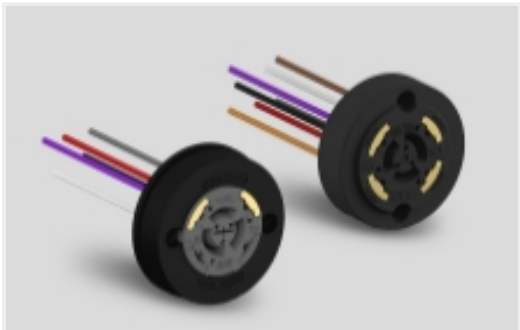

Street Lighting Receptacles(22)



Customers Also Bought



TE Part #2361116-1

LUMAWISE Endurance N+ Shorting Cap

Documents

Product Drawings

Rcpt Assy, w/ intg gasket; PC; dimm 3/2

English

CAD Files

Customer View Model

ENG_CVM_CVM_2376865-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2376865-3_A.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_2376865-3_A.2d_dxf.zip

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

LUMAWISE Endurance N ANSI C136.41 Dimming Receptacle With Integrated Seal

English

Product Specifications

Application Specification

English

Agency Approvals

UL_CERT_CB_4789600659_TR_C1

English

UL_CERT_CB_US_37285_C1

English