



CGS SP

TE Internal #: D93779-000
Self-Laminating, Die-Cut, Permanent Acrylic Adhesive, 50.8 mm [2 in] Width, 57.2 mm [2.25 in] Height, 6.1 – 12.1 mm, CGS SP, Standard Labels

[View on TE.com >](#)

Identification & Labeling > Labels > Standard Labels > SP Self Laminating Polyester Labels



Label Type: **Self-Laminating**
Label Style: **Die-Cut**
Label Adhesive Type: **Permanent Acrylic Adhesive**
Product Width: **50.8 mm [2 in]**
Length of Label Roll: **83.37 m [273.52 ft]**

[All SP Self Laminating Polyester Labels \(8\)](#)

Features

Product Type Features

Printable Label Height	19.1 mm[.75 in]
Label Type	Self-Laminating

Body Features

Primary Product Material	Polyester
--------------------------	-----------

Dimensions

Product Width	50.8 mm[2 in]
Product Height	57.2 mm[2.25 in]
Compatible Cable Diameter Range	6.1 – 12.1 mm[.239 – .477 in]

Usage Conditions

Operating Temperature Range	-40 – 150 °C[-40 – 302 °F]
-----------------------------	----------------------------

Printer/Label Features

Number of Labels Across	2
Label Style	Die-Cut
Length of Label Roll	83.37 m[273.52 ft]
Label Thickness	45 Micron



Packaging Features

Packaging Method	Roll
Packaging Quantity	2500

Other

Label Adhesive Type	Permanent Acrylic Adhesive
---------------------	----------------------------

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 1-2186577-1
T7112DS-SWARE-PRINTER



TE Part # 1-2186576-1
T7112DS-PRINTER



TE Part # 1-2186501-1
T3212-SWARE-PRINTER



TE Part # 1-2186527-1
T2212-PRINTER



TE Part # 1-2186502-1
T3224-PRINTER



TE Part # 1-2186528-1
T2212-SWARE-PRINTER




TE Part # 1-2186500-1
T3212-PRINTER



TE Part # 1-2186503-1
T3224-SWARE-PRINTER


Also in the Series | CGS SP

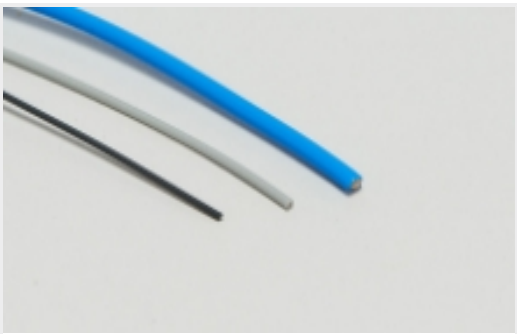

Hook Up Wire(5)




Power Cable(1)

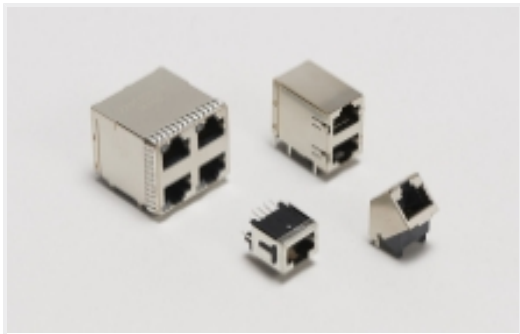

RJ45 Connectors(9)




Standard Labels(8)

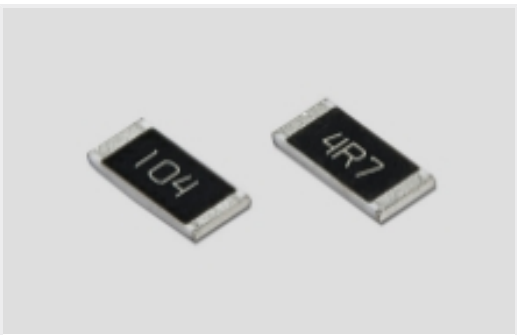

Surface Mount Resistors(36)



Through-Hole Resistors(1)

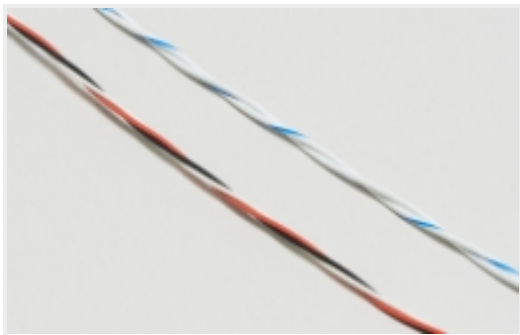

Twisted Pair Cable(1)

Customers Also Bought



TE Part #NB-PTCO-192
Pt1000, 1.2x4.0, Class A, PTFM102A1A0



TE Part #CV25894001
RW-175-E-1/2-X-SP



TE Part #F07599-000
MP-508254-5-8A



TE Part #2-1879026-6
YR1 0.1% 17R8






TE Part #9-1879221-7
CPF 0603 16R9 0.1% 25PPM 1K RL



TE Part #1-1879222-5
CPF 0603 26R7 0.1% 25PPM 1K RL



TE Part #1-1879222-7
CPF 0603 28R 0.1% 25PPM 1K RL

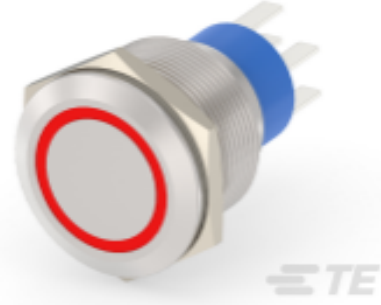

TE Part #6-2213772-7
AV22 DPL 3A MOVE RING LED RED 24V



TE Part #5-6437630-2
FTN7904=FLAT TOGGLE



TE Part #5-6437630-4
FTD79G04=FLAT TOGGLE

Documents

Product Drawings

SP200225WE2.5

English

Datasheets & Catalog Pages

Self Laminating Polyester (SP) Technical Datasheet

English

IDENTIFICATION SELECTION GUIDE

English