

EGT6 EG2/EN**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Do not use product for new
developments

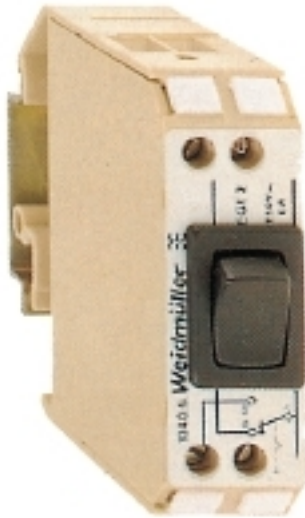

The profiles of the switch and button components match those of the electronic components.

Switches and buttons facilitate commissioning, servicing, monitoring and repair of industrial installations.

General ordering data

Version	, Function component CO contact, sensing, Screw connection
Order No.	0114660000
Type	EGT6 EG2/EN
GTIN (EAN)	4008190180355
Qty.	10 pc(s).
Delivery status	Discontinued
Available until	2024-10-22

EGT6 EG2/EN

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	50 mm	Height (inches)	1.969 inch
Width	18 mm	Width (inches)	0.709 inch
Length	58 mm	Length (inches)	2.283 inch
Net weight	41.9 g		

Temperatures

Storage temperature	-40 °C...100 °C	Operating temperature	-25 °C...85 °C
---------------------	-----------------	-----------------------	----------------

Output

Rated switching voltage	250 V AC	AC switching capacity (resistive), max.	1500 VA @ 250 V
AC switching capacity, max.	1,500 VA	Switching capacity	250 V
DC switching capacity (resistive), max.	180 W @ 30 V	DC switching capacity, max.	180 W
Switching capacity	30 V		

General data

Rail	TS 32, TS 35	Colour	beige
------	--------------	--------	-------

Connection data

Wire connection method	Screw connection	Clamping range, rated connection	6 mm ²
Clamping range, min.	0.5 mm ²	Clamping range, max.	6 mm ²
Wire connection cross section, finely stranded, max.	4 mm ²		

Classifications

ETIM 6.0	EC002498	ETIM 7.0	EC002498
ETIM 8.0	EC002498	ETIM 9.0	EC002498
ETIM 10.0	EC002498	ECLASS 9.0	27-37-92-01
ECLASS 9.1	27-37-92-01	ECLASS 10.0	27-37-13-92
ECLASS 11.0	27-37-13-92	ECLASS 12.0	27-37-13-92
ECLASS 13.0	27-37-13-92	ECLASS 14.0	27-37-13-92
ECLASS 15.0	27-37-13-92		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319222/-T1z1mm-S800/
ROHS	Conform

EGT6 EG2/EN

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Con-
formity

[Application notes – EU Konformitätserklärung / EU Declaration of Conformity](#)

Catalogues

[Catalogues in PDF-format](#)

EGT6 EG2/EN**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Steel**

Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

Type	TS 35X7.5 2M/ST/ZN	Version
Order No.	0383400000	Terminal rail, Accessories, Steel, galvanic zinc plated and passivated,
GTIN (EAN)	4008190088026	Width: 2000 mm, Height: 35 mm, Depth: 7.5 mm
Qty.	40 m	
Type	TS 35X15/2.3 2M/ST/ZN	Version
Order No.	0498000000	Terminal rail, Accessories, Steel, galvanic zinc plated and passivated,
GTIN (EAN)	4008190042493	Width: 2000 mm, Height: 35 mm, Depth: 15 mm
Qty.	20 m	

Steel

Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

Type	TS 32X15 2M/ST/ZN	Version
Order No.	0122800000	Terminal rail, Accessories, Steel, galvanic zinc plated and passivated,
GTIN (EAN)	4008190066307	Width: 2000 mm, Height: 33 mm, Depth: 15 mm
Qty.	20 m	

EGT6 EG2/EN**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****TS 32**TS 32

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	EWK 2	Version
Order No.	0199360000	End bracket, beige, TS 32, V-0, Wemid, Width: 15 mm, 100 °C
GTIN (EAN)	4008190023546	
Qty.	50 pc(s).	

SAK-SeriesSAK
Series

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

Type	EW 35	Version
Order No.	0383560000	End bracket, beige, TS 35, V-2, Wemid, Width: 8.5 mm, 100 °C
GTIN (EAN)	4008190181314	
Qty.	50 pc(s).	