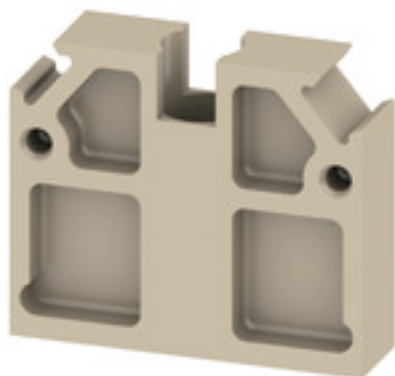


BB 1 AKB 4**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Fixing brackets for our pluggable terminal blocks serve as mechanical fasteners for the respective plugs. They protect both the connector and the contact from mechanical stress and unintentional loosening due to vibration.

General ordering data

Version	Partition plate (terminal), beige, Height: 27 mm, Width: 7 mm, V-2, PA 66
Order No.	0320560000
Type	BB 1 AKB 4
GTIN (EAN)	4008190102555
Qty.	50 pc(s).

BB 1 AKB 4**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	23 mm	Depth (inches)	0.906 inch
Height	27 mm	Height (inches)	1.063 inch
Width	7 mm	Width (inches)	0.276 inch
Net weight	2.34 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Material data

Material	PA 66	Colour	beige
UL 94 flammability rating	V-2		

System specifications

Version	Mounting block
---------	----------------

Additional technical data

Installation advice	Direct mounting	Snap-on	No
---------------------	-----------------	---------	----

General

Installation advice	Direct mounting
---------------------	-----------------

Classifications

ETIM 6.0	EC000886	ETIM 7.0	EC000886
ETIM 8.0	EC000886	ETIM 9.0	EC000886
ETIM 10.0	EC000886	ECLASS 9.0	27-14-11-92
ECLASS 9.1	27-14-11-33	ECLASS 10.0	27-14-11-92
ECLASS 11.0	27-14-11-92	ECLASS 12.0	27-14-11-92
ECLASS 13.0	27-25-03-01	ECLASS 14.0	27-25-03-01
ECLASS 15.0	27-25-03-01		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
------------------	---------------------------------