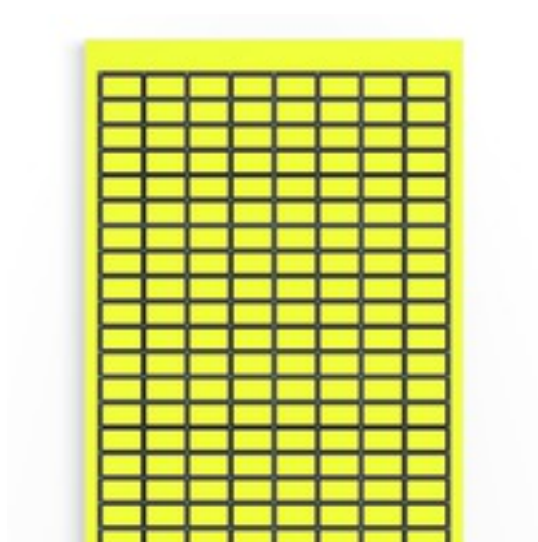


PAGETAB 19/11**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration



PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 11 x 19 mm, yellow
Order No.	1686170000
Type	PAGETAB 19/11
GTIN (EAN)	4008190492564
Qty.	25 pc(s).

Technical data

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	11 mm	Height (inches)	0.433 inch
Width	19 mm	Width (inches)	0.748 inch
Net weight	9.8 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

General data

Adhesive	Permanent acrylic copolymer	
Colour	yellow	
Material	Acrylic-coated fibre webbing	
Material colour according to resistance code	4	
Number of markers per combination	1 Label sheet = 200 Device markers	
Number of markers per packaging unit	5,000	
Number of markers per packaging unit	Number of markers per combination	200
	Number of combinations per packaging unit	25
	Form of supply	Label sheet
Number per sheet	200	
Operating temperature range	-29...93 °C	
Operating temperature range, max.	93 °C	
Operating temperature range, min.	-29 °C	
Printed characters	without	
Printing	Neutral	
Version	Self-adhesive	
Width	19 mm	

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--

Drawings

